

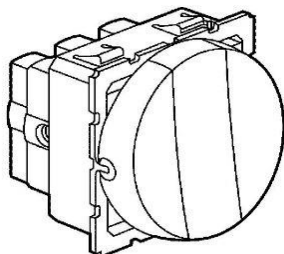
Arteor™

Ref . No. : 573073 / 573173

20A SWITCH 3G 2X2W+1X1W 2M RO

Date : 15/01/2024

Rev.1

**1. USE**

General lighting control mechanism, Gadgets power control mechanism.

2.Type

Two way switch (Round)

No. of modules : 2

Colour : White / Magnesium

Mounting : Flush and Surface - mounted

3.OVERALL DIMENSIONS

Width : 45 mm

Height : 45 mm

Depth : 42.2 mm

Weight (g) : 29.7

4.CONNECTION

Terminal : with screws

Capacity : 2.5mm² to 6mm²

Stripping : 10 mm

Screwdriver : 4mm flat-blade up to 5 mm

5.OPERATION

Switch operating mechanically by rocker toggling

6.TECHNICAL CHARACTERISTICS**6.1 Material Characteristics**

Rocker: Polycarbonate

Base: Polycarbonate

Contact Terminal: Brass

Pivot Terminal: Brass

Screws: Steel with Zinc plating

Terminal plate: Polycarbonate

Cover: Polycarbonate

Plunger: Polycarbonate

Rocker spring: Stainless steel

Transmitter: Polypropylene FR

Contact Tip: Silver

Moving Contact: Brass

6.2 Electricals Characteristics

Voltage :230VAC

Current : 20A

Self - extinguishing : 850° C / 30 s.

7.CONFORMITY - APPROVALS

As per Indian Standard IS 3854:1997