

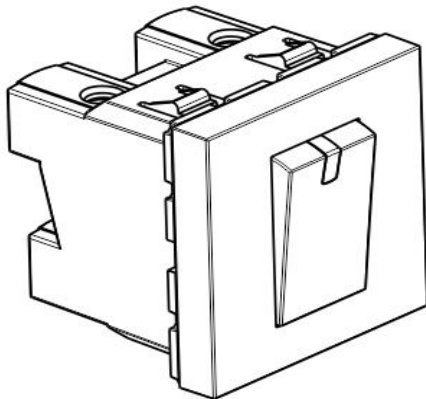
ArteorTM

Ref . No. : 573412

32A DP SWITCH 2M IND White

Date : 21/10/2021

Rev.1

**1. USE**

General lighting control mechanism, Gadgets power control mechanism.

2.Type

One Way Switch with indicator (Square) Double Pole

No. of modules : 2

Colour : White

Mounting : Flush and Surface - mounted

3.OVERALL DIMENSIONS

Width : 45 mm

Height :45 mm

Depth : 42.5 mm

Weight (g) : 61.3

4.CONNECTION

Terminal : with screws

Capacity : 2.5mm² to 10mm²

Stripping : 10 mm

Screwdriver : 4mm flat-blade up to 5 mm

5.OPERATION

Switch with rocker

6.TECHNICAL CHARACTERISTICS**6.1 Material Characteristics**

Front cover : Polycarbonate

Rocker : Polycarbonate

Base : Polycarbonate

Lens : Polycarbonate Red

Terminal : Brass with silver plating

Screws : Steel with Zinc Plating

Plunger : PA66 + 20%SI + PTEE

Under cover : Polycarbonate

Plunger spring : Steel

Moving Contact : Copper

L/N Pivot Contact : Copper

L/N Fixed Contact : Copper

Clamp Screw : Steel with zinc plating

Contact Tip : Copper

6.2 Electricals Characteristics

Voltage :230V AC

Current : 32A

Self - extinguishing : 850° C / 30 s.

7.CONFORMITY - APPROVALS

As per IS : 3854