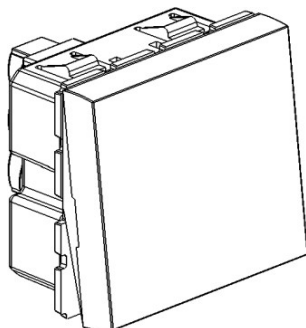


Arteor™
Ref . No. : 573450 – 573650 – 574804
10AX Switch SP 2Mod. 1Way
Date : 18/05/2015
Rev.1

1. USE

General lighting control mechanism .

2.Type

One way switch (square) single pole

No. of modules : 2

Colour : 573450 – White

573650 – Magnesium

574804 – Champagne

Mounting : Flush and Surface -mounted

3.OVERALL DIMENSIONS

Width : 45 mm

Height : 45 mm

Depth : 42.2 mm

Weight (g) : 27.35

4.CONNECTION

Terminal : with screws

 Capacity : 1mm² to 2.5mm²

Stripping : 10 mm

Screwdriver : 4mm flat-blade up to 5 mm

5.OPERATION

Switch with rocker

6. TECHNICAL CHARACTERISTICS
6.1 Material Characteristics

Rocker : Polycarbonate

Base : Polycarbonate

Basket : Polypropylene

Contact Terminal : Brass with tin plating

Pivot Terminal : Brass with tin plating

Screws : Brass with tin plating

Cover : Polycarbonate

Plunger : Polycarbonate

Rocker spring : Stainlesssteel

Transmitter : polypropylene

Contact Tip : Silver

Moving Contact : Brass

6.2 Electricals Characteristics

Voltage : 230V/250V AC

Current : 10A

Self - extinguishing : 850° C / 30 s.

7.CONFORMITY - APPROVALS

As per IS : 3854