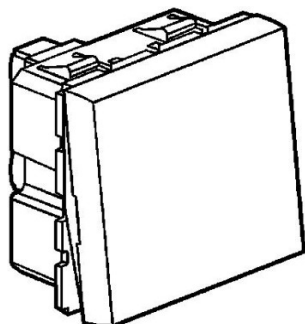


Arteor™
Ref . No. : 573452 – 573652 – 574809
20A Switch SP 2Mod. 1Way

Date : 09/09/2021

Rev.2


1. USE

General lighting control mechanism .

2.Type

One way switch (square) single pole

No. of modules : 2

Colour : 573452 - White

573652 - Magnesium

574809 - Champagne

Mounting : Flush and Surface - mounted

3.OVERALL DIMENSIONS

Width :45 mm

Height :45 mm

Depth : 30 mm

Weight (g) : 31.85

4.CONNECTION

Terminal : with screws

 Capacity : 2.5mm² to 6mm²

Stripping : 10 mm

Screwdriver : 4mm flat-blade up to 5 mm

5.OPERATION

Switch with rocker

6. TECHNICAL CHARACTERISTICS
6.1 Material Characteristics

Rocker : Polycarbonate

Base : Polycarbonate

Basket : Polypropelene

Contact Terminal : Brass with silver plating

Pivot Terminal : Brass with silver plating

Screws : Brass with silver plating

Cover : Polycarbonate

Plunger : Polycarbonate

Rocker spring : Stainlesssteel

Transmitter : polypropelene

Contact Tip : Silver

Moving Contact : Brass with silver plating

6.2 Electricals Characteristics

Voltage :230V/250V AC

Current : 20A

Self - extinguishing : 850° C / 30 s.

7.CONFORMITY - APPROVALS

As per IS : 3854