

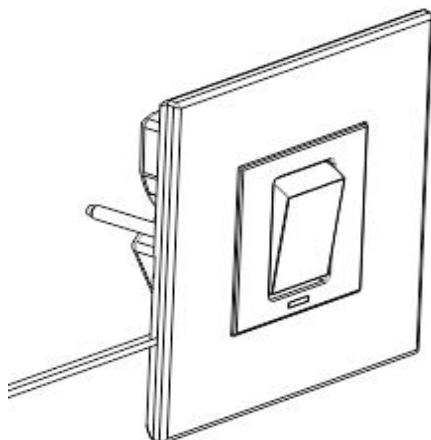
Arteor™

Ref . No. : 573530

40A SWITCH DP IND WHITE

Date : 02.11.2021

Rev.1

**1. USE**

General lighting control mechanism.

2.Type

One way Switch (Square) Double Pole

No. of modules : 2

Colour : White

Mounting : Flush and Surface - mounted

3.OVERALL DIMENSIONS

Width : 92 mm

Height :92 mm

Depth : 34 mm

Weight (g) : 140

4.CONNECTION

Terminal : with screws

Capacity : 6 mm² to 16 mm²

Stripping : 24 mm

Screwdriver : 4mm flat-blade up to 5 mm

5.OPERATION

Switch with rocker

6. TECHNICAL CHARACTERISTICS**6.1 Material Characteristics**

Front Plate: Polycarbonate

Under Plate: ABS

Cap: Polycarbonate

Rocker: Polycarbonate

Cover : Polypropylene

Lens : Polycarbonate

Tip Terminal : Brass

Pivot Terminal : Brass

Screws : Brass with Silver Plating

Rocker spring : Stainless steel

Contact Tip : Silver

Moving Contact : Brass

Base: Polycarbonate

6.2 Electricals Characteristics

Voltage :230V AC

Current : 40A

Self - extinguishing : 850° C / 30 s.

7.CONFORMITY - APPROVALS

As per IS : 3854