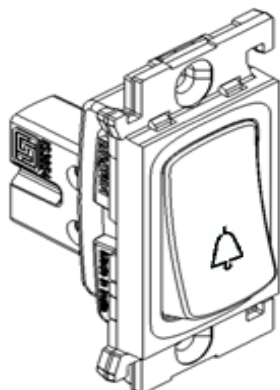


Mylinec™
Ref . No. : 675504
6A Bell Push 1M 1Way-White
Date : 05-09-2023
Rev.2

1. USE

To Operate Bell or Buzzer.

2.Type

One way switch single pole

No. of modules : 1

Colour : White

Mounting : Flush and Surface - mounted

3.OVERALL DIMENSIONS

Width : 28 mm

Height :57.2 mm

Depth :35 mm

Weight (g) : 18

4.CONNECTION

Terminal : with screws

Capacity : 0.75mm² to 1.5mm²

Stripping : 10 mm

Screwdriver : 4mm flat-blade up to 5 mm

5.OPERATION

Switch operating mechanically by rocker toggling

6.TECHNICAL CHARACTERISTICS
6.1 Material Characteristics

Rocker : Polycarbonate

Front Cover :Polycarbonate

Base : Polypropylene

Contact Terminal : Brass

Pivot Terminal : Brass

Screws : Steel with zinc plating

Rocker spring : Stainlesssteel

push spring : Stainlesssteel

Transmitter : Polypropylene

Contact Tip : Silver

Moving Contact : Brass

6.2 Electricals Characteristics

Voltage : 230V AC

Current : 6A

Self - extinguishing : 850° C / 30 s

Bell

7.CONFORMITY - APPROVALS

As per IS : 3854