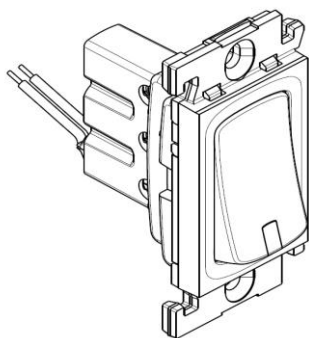


Mylinec™
Ref . No. : 675513
16AX Switch 1M 1Way with indicator
Date : 05-09-2023
Rev.2

1. USE

General lighting control mechanism .

2.Type

One Way Switch (Square) single pole
 No. of modules : 1
 Colour : White
 Mounting : Flush and Surface - mounted

3.OVERALL DIMENSIONS

Width : 23.5 mm
 Height :57.25 mm
 Depth : 32.8 mm
 Weight (g) : 22

4.CONNECTION

Terminal : with screws
 Capacity : 1.5mm² to 4.0mm²
 Stripping : 10 mm
 Screwdriver : 4mm flat-blade up to 5 mm

5.OPERATION

Switch with rocker

6.TECHNICAL CHARACTERISTICS
6.1 Material Characteristics

Rocker with indicator : Polycarbonate
 Front Cover : Polycarbonate
 Lens : Polycarbonate red
 Base : Polypropelene
 Contact Terminal : Brass
 Pivot Terminal : Brass
 Screws : Steel with zinc plating
 Rocker spring : Stainlessteel
 Transmitter : polypropelene
 Contact Tip : Silver
 Moving Contact : Brass

6.2 Electricals Characteristics

Voltage : 230V AC
 Current : 16A
 Self - extinguishing : 850° C / 30 s.

7.CONFORMITY - APPROVALS

As per IS: 3854