

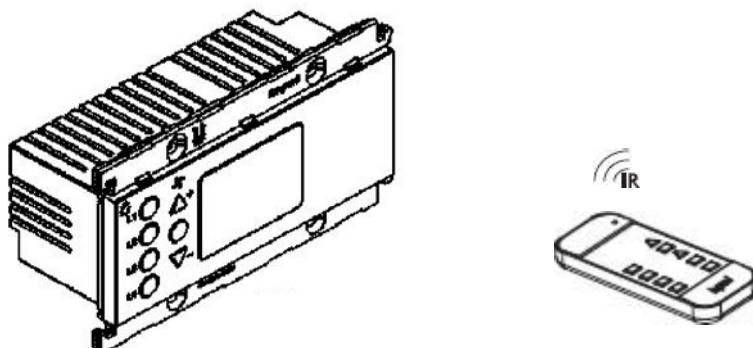
Mylinc™

Ref. No. : 675975 / 676347

REMOTE CONTROL UNIT FOR LIGHT AND FAN 4MOD

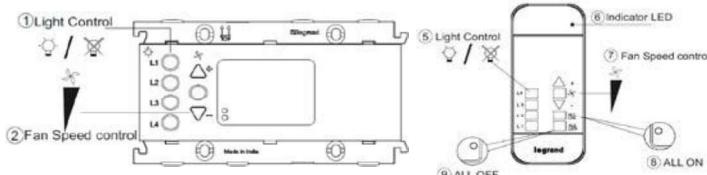
Date : 26/04/18

Rev.1

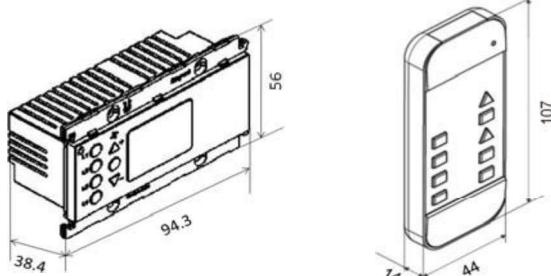

1. USE

As a control unit to switch ON / OFF four lights and increase/decrease fan speed with remote control.

For domestic indoor application.


2. RANGE
Myrius

Cat No	Description	Finish
675975	Remote control unit for light and Fan	White
676347	Remote control unit for light and Fan	Grey

3. OVERALL DIMENSION (mm)

4. CONNECTION

Type of terminals: with screws

Terminal capacity: 1 x 2.5 sq.mm

Stripping length: 8 mm

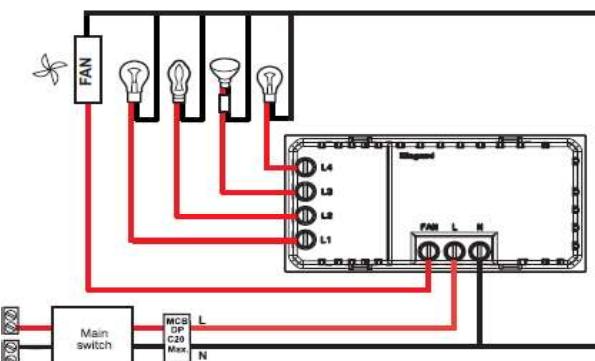
Screwdriver: flat 3.5 mm

5. CLEANING

Surface cleaning with a cloth.

Do not use: acetone, tar remover, trichlorethylene.

Caution: A preliminary test should be carried out if specific cleaning products are to be used

6. INSTALLATION
Wiring Diagram

7. TECHNICAL CHARACTERISTICS
7.1 Climatic characteristics

Operating temperature: 0° C to 40° C

7.2 Electrical characteristics

Nominal input voltage	240 VAC (+/- 2%)
-----------------------	-------------------

Nominal input frequency	50 Hz
-------------------------	-------

8. UTILIZATION

40° 0° 240V AC 50Hz	①	②	③	④	⑤	⑥
Max.	1x2.5mm ²	400 VA	200 VA	200 VA	150 VA	100W

1. Incandescent bulbs.
2. Halogen lamp 230V~
3. Low voltage halogen lamps.
4. Fluorescent tube light.
5. Ceiling Fan (OFF + 4 Variable speed steps)
6. LED Lamps.

9. BATTERY
9.1 Replacement
9.2 Type

Battery type

Button Cell - CR 2032 3V

