

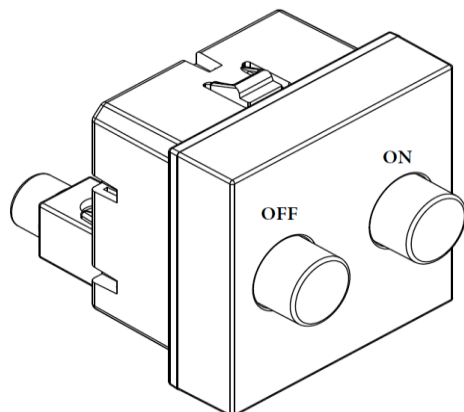
Lyncus™

Ref . No. : 677272

Motor Starter 25A White 2M

Date :20/03/2019

Rev.1

**1. Use**

Overload protection

2.Type

Single Phase Motor Starter

No. of modules : 2M

Colour : White

Mounting : Flush and Surface - mounted

3.OVERALL DIMENSIONS

Width : 45 mm

Height : 45 mm

Depth : 59 mm

Weight (g) : 67

4.CONNECTION

Terminal : with screws

Capacity : 1.5mm² to 6mm²

Screwdriver : 4mm flat-blade up to 5 mm

5.OPERATION

Push Type Knob for ON : Green colour and OFF : Red colour

6.TECHNICAL CHARACTERISTICS**6.1 Material Characteristics**

Start (Knob) : Polyamide (PA6)

Stop (Knob) : Polyamide (PA6)

Top Plate : Polycarbonate

Intermediate Cover : Polybutylene terephthalate (PBT) + Glassfilled(30%)

Base : Polybutylene terephthalate (PBT) + Glassfilled(30%)

Screws : Brass with silver plating

Terminal : Brass with silver plating

6.2 Electricals Characteristics

Voltage :240V AC

Current : 25A

6.3 Marking

Rating ,Voltage , ON-OFF indication , Made in India,Single phase motor Starter ,Traceability

7.CONFORMITY - APPROVALS

As per Legrand Company Standard