

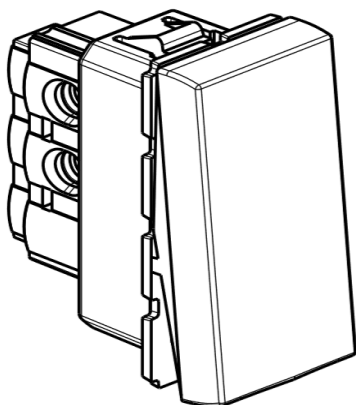
LyncusTM

Ref . No. : 677412

20A SWITCH 1W1M GREY

Date : 28/03/2019

Rev.1

**1. USE**

General lighting control mechanism .

2.Type

One Way Switch (Square) Single Pole

No. of modules : 1

Colour : Chic Grey

Mounting : Flush and Surface - mounted

3.OVERALL DIMENSIONS

Width : 22.5 mm

Height :45 mm

Depth : 40 mm

Weight (g) : 19

4.CONNECTION

Terminal : with screws

Capacity : 2.5mm² to 6mm²

Stripping : 10 mm

Screwdriver : 4mm flat-blade up to 5 mm

5.OPERATION

Switch with rocker

6.TECHNICAL CHARACTERISTICS**6.1 Material Characteristics**

Rocker : Polycarbonate Grey

Upper Base : Polycarbonate

Basket : Polypropelene

Plunger : Polycarbonate

Tip Terminal : Brass

Pivot Terminal : Brass

Screws : Steel with zinc plating

Rocker spring : Stainlesssteel

Transmitter : Polypropelene

Contact Tip : Silver

Moving Contact : Brass

6.2 Electricals Characteristics

Voltage :230V AC

Current : 20A

Self - extinguishing : 850° C / 30 s.

7.CONFORMITY - APPROVALS

As per IS : 3854