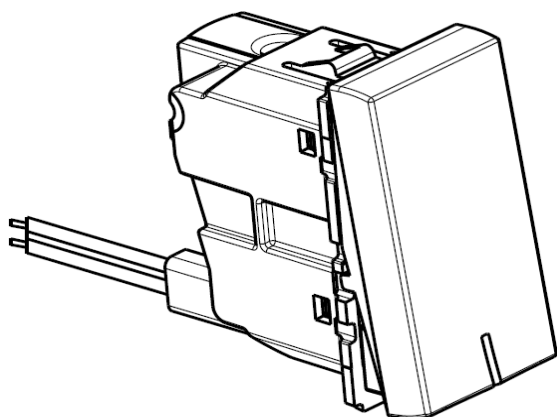


Lyncus™
Ref . No. : 677416
25A SP 1W SW IND 1M GREY
Date : 20/03/2019
Rev.1

1. USE

General lighting control mechanism .

2.Type

One Way Switch with indicator (Square) single Pole

No. of modules : 1

Colour : Chic Grey

Mounting : Flush and Surface - mounted

3.OVERALL DIMENSIONS

Width : 22.5 mm

Height :45 mm

Depth : 40.8 mm

Weight (g) : 28.5

4.CONNECTION

Terminal : with screws

Capacity : 2.5mm² to 6mm²

Stripping : 10 mm

Screwdriver : 4mm flat-blade up to 5 mm

5.OPERATION

Switch with rocker

6.TECHNICAL CHARACTERISTICS
6.1 Material Characteristics

Rocker : Polycarbonate Grey

Base : Polycarbonate

Lens : Polycarbonate Red

Terminal : Brass with Silver plating

Screws : Brass with Tin plating

Transmitter : PA66 + 20%SI + PTFE

Plunger : Polycarbonate

Cover : Polycarbonate

6.2 Electricals Characteristics

Voltage :230V AC

Current : 25A

Self - extinguishing : 850° C / 30 s.

7.CONFORMITY - APPROVALS

As per IS : 3854