

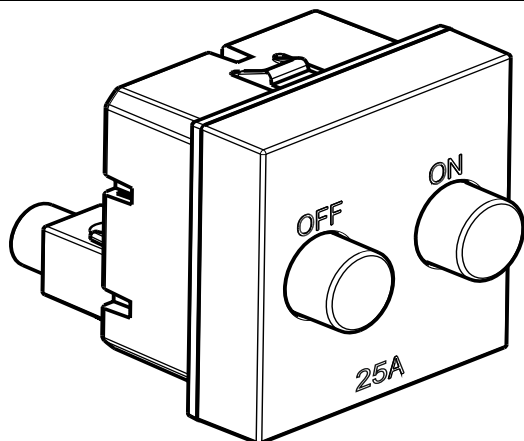
Myrius™

Ref . No. : 679472

25A MOTOR STARTER 2M CHARCOAL GREY

Date : 20/05/2020

Rev.1

**1. USE**

Overload protection

2.TYPE

Single Phase Motor Starter

No. of modules : 2M

Colour : Charcoal Grey

Mounting : Flush and Surface -mounted

3.OVERALL DIMENSIONS

Width : 45 mm

Height : 45 mm

Depth : 59 mm

Weight (g) : 67

4.CONNECTION

Terminal : with screws

Capacity : 1.5mm² to 6mm²

Screwdriver : 4mm flat-blade up to 5 mm

5.OPERATION

Push Type Knob for ON : Green colour and OFF : Red colour

6.TECHNICAL CHARACTERISTICS**6.1 Material Characteristics**

Start (Knob) : Polyamide(PA6)

Stop (Knob) : Polyamide(PA6)

Top Plate : Polycarbonate

Intermediate Cover : Polybutylene Terephthalate (PBT) + Glassfilled(30%)

Base : Polybutylene Terephthalate (PBT) + Glassfilled(30%)

Screws : Brass with silver plating

Terminal : Brass with silver plating

6.2 Electricals Characteristics

Voltage : 240V AC

Current : 25A

6.3 Marking

Rating, Voltage, ON-OFF indicator, Made in India, Single phase motor starter, Traceability

7.CONFORMITY - APPROVALS

As per Legrand Standard