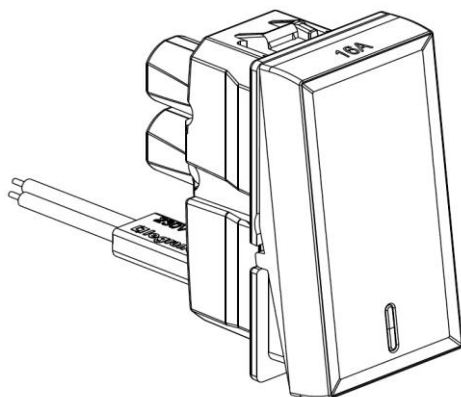


Allzy™
Ref . No. : 681105
16AX SWITCH 1 WAY SP 1M IND WHITE
Date : 03/02/2023 Rev.2

1. USE

General lighting control mechanism

2.Type

One Way Switch with indicator (Square) Single Pole

No. of modules : 1

Colour : White

Mounting : Flush and Surface - mounted

3.OVERALL DIMENSIONS

Width : 22.5 mm

Height :45 mm

Depth : 45 mm

Weight (g) : 16.6

4.CONNECTION

Terminal : with screws

 Capacity : 1.5mm² to 2.5mm²

Stripping : 10 mm

Screwdriver : 4mm flat-blade up to 5 mm

5.OPERATION

Switch with rocker

6.TECHNICAL CHARACTERISTICS
6.1 Material Characteristics

Rocker : Polycarbonate

Base : Polypropelene

Lens : Polycarbonate

Contact Terminal : Brass

Pivot Terminal : Brass

Screws : Steel with Zinc plating

Rocker spring : Stainless steel

Transmitter : Polypropelene

Plunger: Polycarbonate

Contact Tip : Bi-metal (Cu+AgNi)

Moving Contact : Brass with Bi-metal tip

LED Indicator : Electronic

6.2 Electricals Characteristics

Voltage : 230V AC

Current : 16AX

Self - extinguishing : 850° C / 30 s.

7.CONFORMITY - APPROVALS

As per Indian Standard IS 3854:1997