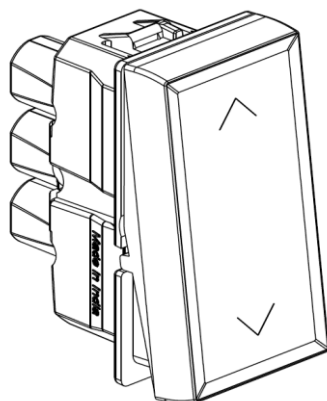


Allzy™

Ref . No. : 681111

6AX SWITCH 2 WAY SP 1M WHITE

Date : 03/02/2023 Rev.2

**1. USE**

General lighting control mechanism .

**2.Type**

Two Way Switch (Square) Single Pole

No. of modules : 1

Colour : White

Mounting : Flush and Surface - mounted

**3.OVERALL DIMENSIONS**

Width : 22.5 mm

Height :45 mm

Depth :37.8 mm

Weight (g) : 16.6

**4.CONNECTION**

Terminal : with screws

Capacity : 0.75mm<sup>2</sup> to 1.5mm<sup>2</sup>

Stripping : 10 mm

Screwdriver : 4mm flat-blade up to 5 mm

**5.OPERATION**

Switch with rocker

**6.TECHNICAL CHARACTERISTICS****6.1 Material Characteristics**

Rocker : Polycarbonate

Base : Polypropylene

Contact Terminal : Brass

Pivot Terminal : Brass

Screws : Steel with Zinc plating

Rocker spring : Stainless steel

Transmitter : Polypropylene

Plunger: Polycarbonate

Contact Tip : Bi-metal (Cu+AgNi)

Moving Contact : Brass with Bi-metal tip

**6.2 Electricals Characteristics**

Voltage : 230V AC

Current : 6AX

Self - extinguishing : 850° C / 30 s.

**7.CONFORMITY - APPROVALS**

As per Indian Standard IS 3854:1997