

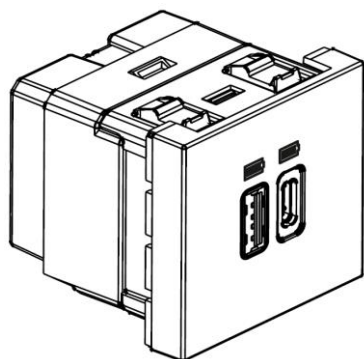
Allzy™

Ref . No. 681170

USB CHARGER 3000mA 2M TYPE A+C White

Date : 07/11/2022

Rev.1

**1. USE**

For recharging portable devices such as smartphones, tablets, MP3 or MP4 players, speakers, watches, game consoles, powerbanks which have type A and C plugs.

2.Type

USB CHARGER 2M TYPE A+C

No. of modules : 2

No. of output port : 2 (Type-A & Type-C)

Colour : White

Mounting : Flush box and Surface box-mounted

3.OVERALL DIMENSIONS

Width : 45 mm

Height : 45 mm

Depth : 42 mm

Weight (g) : 59

4.CONNECTION

Type of terminals: with screws

Terminal capacity: 1 x 2.5 mm²

Stripping length: 6 mm

Screwdriver: flat 3.5 mm

5.CLEANING

Surface cleaning with a cloth.

Do not use: acetone, tar remover, trichlorethylene.

6. TECHNICAL CHARACTERISTICS**▪ 6.1 Climatic characteristics**

Storage temperature: - 20° C to + 70° C

Operating temperature: 0° C to + 45° C

▪ 6.2 Electrical characteristics

All values listed below are measured at an ambient temperature of + 25° and after 15 minutes of operation.

1) Nominal input voltage - 100-240 VAC

2) Nominal input frequency - 50-60 Hz

3) Maximum input current- 500mA

4) Power average efficiency >80%

5) Maximum power consumption in standby - 75 mW

6) Nominal output voltage - 5VDC

7) Maximum output current- 3000mA

8) Protection ClassII - Low voltage

7.CONFORMITY - APPROVALS

▪ IEC 60950-1: low voltage directive.

▪ Conforming IS 13252(Part-1) : 2010+A1 : 2013+A2 :2015

Registered under compulsory registration scheme from Bureau of Indian Standards (Mandatory) . Granted with unique registration number.