

Central container

4210

Description

Metal white enclosure with side opening and key lock.
 Fitted with fuse-holder, 2A fuse, antitamper/anti-tear off microswitch and already wired switching power supply.
 Container 4210 recommended for 16-zone central unit (dimensions 255x295x85mm; 1.7A switching power supply)

Certification: EN 50131 Index 3 Environmental Class II

Related items

4200 16-IP central unit card
 4201 48-IP central unit card
 4203 128-IP central unit card
 4204 16 central unit card


Technical data

Supply voltage	110 – 240 Vac; 50 – 60 Hz
Absorption	0.4 A max
Output switching power supply	14.2V; 1.7 A
Housable battery	7.2 A/h; 12 V

Dimensional data

Size: 295 x 255 x 85mm (H x L x D)

Front view without cover

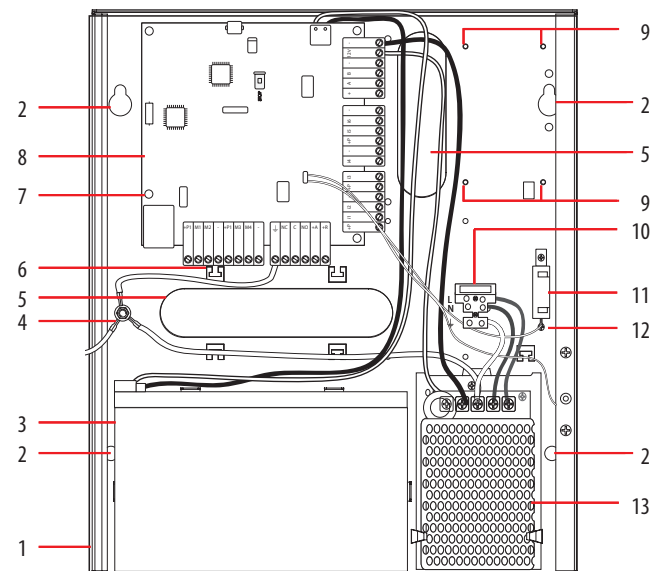

Legend

1. Metal bottom
2. Holes for fixing the box to the wall
3. Battery 12V; 7.2Ah (not supplied)
4. Earthing connections
5. Slots for cable entry
6. Cable fastening
7. Supports to fasten the central unit card
8. Central card (not supplied)
9. Holes to fasten PSTN communicator or expansion modules
10. Fuse 2A
11. Anti-tampering microswitch
12. Microswitch connector + cable
13. Switching power supply