

Central container

4211

Description

Metal white enclosure with side opening and key lock.
 Fitted with fuse-holder, 2A fuse, antitamper/anti-tear off microswitch and already wired switching power supply.
 Container 4211 recommended for 48 and 128-zone central unit (dimensions 325x400x90mm; 3A switching power supply)

Certification: EN 50131 Index 3 Environmental Class II

Related items

4200	16-IP central unit card
4201	48-IP central unit card
4203	128-IP central unit card
4204	16 central unit card


Technical data

Supply voltage	110 – 240 Vac; 50 – 60 Hz
Absorption	0.8 A max
Output switching power supply	14.2 V; 3 A
Housable battery	18 A/h; 12 V

Dimensional data

Size: 400 x 325 x 90mm (H x L x D)

Front view without cover

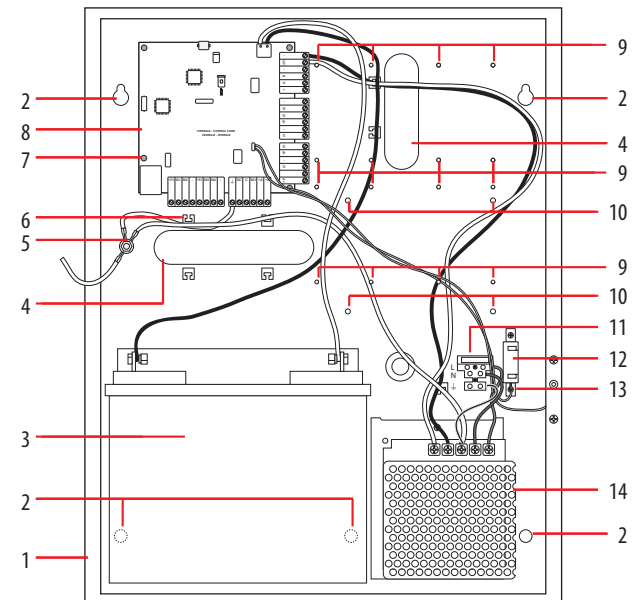

Legend

1. Metal bottom
2. Holes for fixing the box to the wall
3. Battery 12V;18Ah (not supplied)
4. Slots for cable entry
5. Earthing connections
6. Cable fastening
7. Supports to fasten the central unit card
8. Central card (not supplied)
9. Holes to fasten the zone-expansion module or PSTN
10. GSM module fixing holes
11. Fuse 2A
12. Anti-tampering microswitch
13. Microswitch connector + cable
14. Switching power supply