

Datasheet

Plug base 10A for panel-mounting

CAT. NO. 38A0WE



A brand of legrand®



Cat. No.	38A0WE
Description	Plug Base 10A
Colour	White
Nominal Input Voltage	230 - 240 V a.c. 50 Hz
Nominal Current	10 A
Pin Configuration	3 flat pins
Mounting Type	Panels 1 mm thick
Mounting torque	0.2-0.3 Nm
Cut-out Size	Refer diagrams for Profile 1 & 2 (back page)
Dimensions (W x H x D)	38 x 38 x 25 mm
Compliance	AS/NZS 3112, RoHS

Plug base 10A for panel-mounting

CAT. NO. 38A0WE



A brand of **legrand**




- Flush design
- Suitable for panel mounting 1mm thick

Single product		
Cat. No.	Barcode	Dimensions (W x H x D)
38A0WE	9321001015178	140 x 90 x 40 mm

Inner Box (QTY 10)		
Cat. No.	Barcode	Dimensions (W x H x D)
38A0WE	9321001415213	200 x 130 x 77 mm

Outer Box (QTY 200)		
Cat. No.	Barcode	Dimensions (W x H x D)
38A0WE	9321001186076	340 x 247 x 270 mm

DIMENSIONS

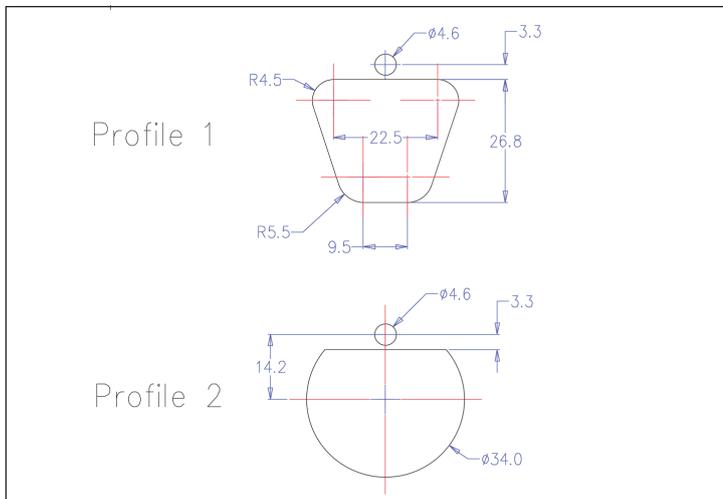

Note: When mounting on 1mm thick panels, you might notice a slight movement of the front part. The socket is still be safe to use, provided the front screw is tightened to 0.2-0.3 Nm torque.

Legrand - Australia
1300 369 777
www.legrand.com.au
ABN 31 000 102 661

Legrand - New Zealand
0800 476 009
www.legrand.co.nz

Refer to your group buying office, Legrand Sales Representative or Legrand Sales Office for pricing.

Please note: specifications are subject to change without prior notice.