

Datasheet

SERENE AC CEILING FAN REMOTE CONTROL KIT

CAT. NO. **CFSERACREMOTE**



A brand of **legrand**



CFSEACREMOTE

PRODUCT SPECIFICATIONS

Cat. No.	CFSEACREMOTE
Description	Serene AC Ceiling Fan Remote Control Kit
Colour/Finish	White
RECEIVER	
Supply Voltage	230-240 V ~ 50 Hz
Stand-by	<0.5 W
Output Rating Fan Motor	100 W MAX
Output Rating LED Light	20 W MAX
Mounting	Slide into hang sure ceiling bracket
Connection Type	Fast connect wiring
Antenna	Discretely located inside top cowling
TRANSMITTER	
Transmitter Type	Radio Frequency (RF)
RF Detection Range	Up to 10 m
Adjustable Fan Speed	Off - Low - Medium - High
Light	ON/OFF*
Light Dimming	Dimmable with wall control, not dimmable by remote control
Adjustable Time Delay	1H - 2H - 4H - 8H
Battery	2 x 1.5V - AAA (batteries included)

*Light function works only with Serene AC ceiling fans that has a light.

Datasheet

SERENE AC CEILING FAN REMOTE CONTROL KIT


CAT. NO. **CFSERACREMOTE**



A brand of **legrand**

FEATURES AND BENIFITS

- Remote control compatible only with HPM range of Serene AC ceiling fans.
- 3 speed fan controller with 4 timers, fan ON/OFF and light ON/OFF + wall mounted holder.

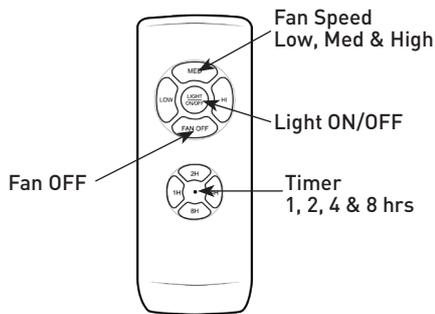

SHIPPING

Single Product			
Cat. No.	Barcode	Packaging Dimensions (mm)	Product Weight (kg)
CFSERACREMOTE	9321001516286	80 x 75 x 150	0.240

Outer Box Qty (40)			
Cat. No.	Barcode	Packaging Dimensions (mm)	Outer Box Weight (kg)
CFSERACREMOTE	9321001523468	640 x 435 x 175	10.8

Legrand - Australia
1300 369 777
www.hpm.com.au
ABN 31 000 102 661

Legrand - New Zealand
0800 476 009
www.hpm.co.nz

Refer to your group buying office, Legrand Sales Representative or Legrand Sales Office for pricing.

Please note: specifications are subjected to change without prior notice.

LE14561AA



07/2023