

Data Sheet

Ceiling Exhaust Fan Kit - Duct and External Grille

CAT NO. EFD01RDWEKIT



A brand of **legrand**



EFD01RDWEKIT


Cat. No.	EFD01RDWEKIT
Description	Round Ducted Ceiling Exhaust Fan kit with Duct and External Grille
Colour	White
Supply Voltage	230 - 240V a.c ~ 50 Hz
Power Rating	40W max
Air Flow Rate	330 m ³ /hr max (Airflow depends on installation conditions)
Class of protection	Class II
Grille Size (Ceiling fan)	Ø372mm
Projection into ceiling	190mm
Hole cut-out size (Ceiling fan)	Ø298mm
IP rating	IPX4 *
Power cord length	70cm
Application	Ceiling
Sound Pressure Level at 3m	36dBA (Tested in accordance with AS 1217.5)
Warranty	3 Year

Ceiling Exhaust Fan Kit - Duct and External Grille

CAT NO. EFD01RDWEKIT



A brand of **legrand**

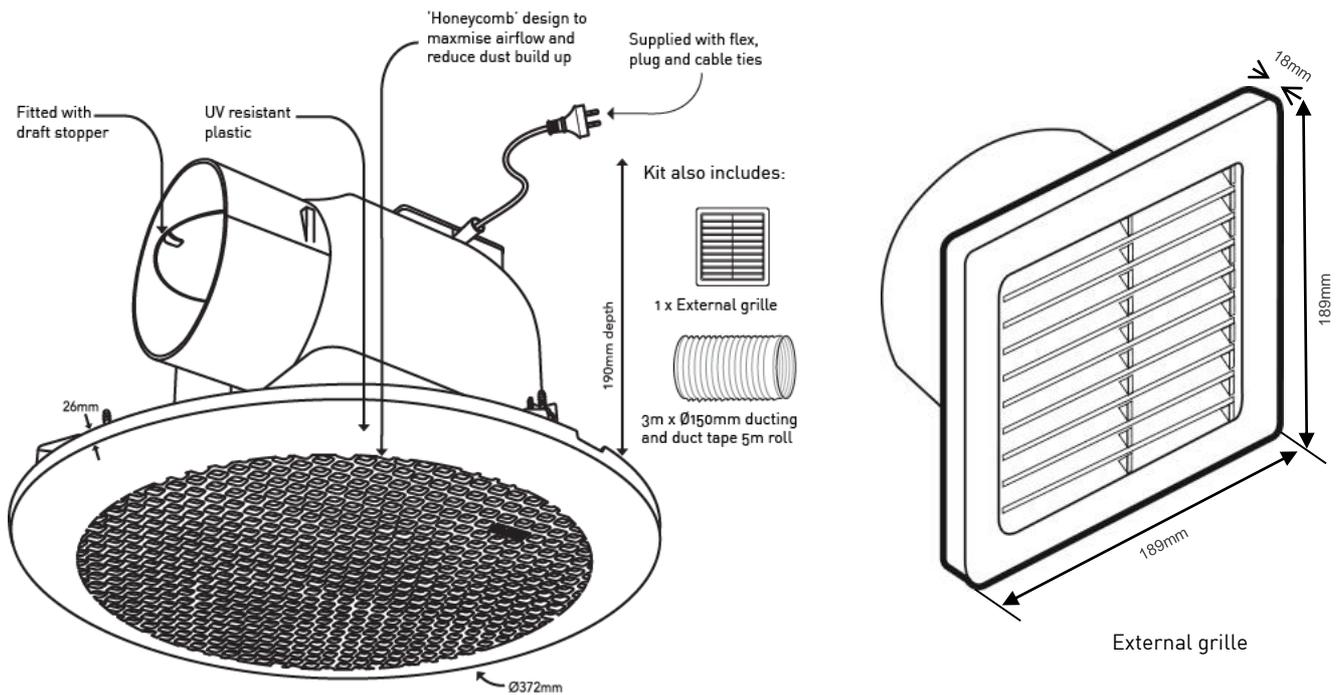

- Ideal for bathroom, kitchens and laundries.
- Kit includes: External grille with mesh, Ø150mm x 3m Duct, Cable ties and Duct tape roll, Instruction Sheet and Warranty Card.
- It encourages air circulation and steam reduction.
- Features a centrifugal fan designed to be ducted outside.
- Airflow measured at 250m³/hr with Ø150mm x 3m long duct.
- Not compatible with after market duct kits.
- *Not recommended for Zone1 Installation as per AS/NZS 3000.

Single Unit		
Cat No.	Barcode	Dimension
EFD01RDWEKIT	9321001488347	492 X 430 X 492mm

Legrand - Australia
1300 369 777
www.legrand.com.au
ABN 31 000 102 661

Legrand - New Zealand
0800 476 009
www.legrand.co.nz

Refer to your group buying office, Legrand Sales Representative or Legrand Sales Office for pricing.

Please note: specifications are subject to change without prior notice.