

Data Sheet

VIVO™

2 Gang Switch Grid & Mechanism only, 10A

CAT NO. EV770/2GMWE, EV770/2GMGR



A brand of legrand®



EV770/2GMWE



EV770/2GMGR

Cat No.	EV770/2GMWE	EV770/2GMGR
Description	Vivo™ 2 Gang Switch Grid & Mechanism only, 10A	
Colour	White (WE)	Dark Grey (GR)
Supply voltage	230-240V a.c.	
Current rating	10A, 10AX (fluoro)	
Mounting centres	84mm	
Compliance	AS/NZS 3133	

VIVO™

2 Gang Switch Grid & Mechanism only, 10A

CAT NO. EV770/2GMWE, EV770/2GMGR



A brand of **legrand**



EV770/2GMWE



EV770/2GMGR



- Fluoro rated up to 10A
- More fixing options - 4 corners
- Oval 84mm fixing points - make it easier to straighten products at the last minute
- Assembly with VIVO™ coverplates

Single product (Qty 1)		
Cat No.	Barcode	Dimensions (W x H)
EV770/2GMWE	9321001465683	101 x 212mm
EV770/2GMGR	9321001465713	101 x 212mm

Inner box (Qty 10)		
Cat No.	Barcode	Dimensions (W x H x D)
EV770/2GMWE	9321001466932	163 x 174 x 124mm
EV770/2GMGR	9321001466963	163 x 174 x 124mm

Outer box (Qty 120)		
Cat No.	Barcode	Dimensions (W x H x D)
EV770/2GMWE	9321001468172	387 x 272 x 515mm
EV770/2GMGR	9321001468202	387 x 272 x 515mm

Glass and tile cut-out dimensions:

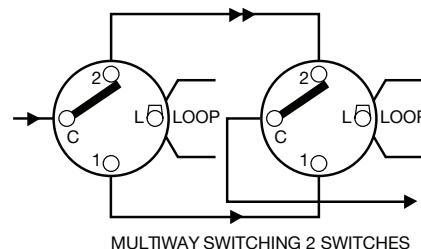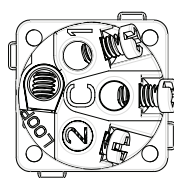

Legrand Australia
1300 369 777
www.hpm.com.au
ABN 31 000 102 661

Legrand New Zealand
0800 476 009
www.hpm.co.nz

Refer to your group buying office, Legrand Sales Representative or Legrand Sales Office for pricing.

Please note: specifications are subject to change without prior notice.