

Datasheet

Inspire Smart Ceiling Fan Plywood with Light

CAT. NO. RCFL12H4BTWE



A brand of **legrand**



Non-Dimmable



Control via HPM Connect App and Remote Control

Technical Specifications	
FAN	
Description	Inspire Smart Ceiling Fan Plywood with Light, 4 Blades, 1220mm, 48", Hangsure
Colour	White
Fan	230- 240 V a.c. 50 Hz 50 W (motor)
Airflow	7680 m ³ /h
Fan Power	Hi:50 W, Med:26 W, Low:13 W
Fan Power Factor	0.95 @ 240 V a.c. 50 Hz
Standby Power	0.4 W
LAMP	
Type	with Integrated LED Light
Wattage	15 W
Lumen	900 lm
Efficacy	60 lm/W
Light Colour	Warm White, Cool White, Natural White
Power Factor	0.5 @ 240 V a.c. 50 Hz
CRI	80+

Remote	
Features	<ul style="list-style-type: none"> ■ 1.5 V 2 x AAA Batteries (Not Included) ■ Wall Mounting Bracket included
Functions	<ul style="list-style-type: none"> ■ Control Light (ON/OFF) ■ Fan Speed Control ■ Timer (Fan only) ■ Wireless Reset ■ Remote Operation Range (10m free air)



Download the App



Learn more

Inspire Smart Ceiling Fan Plywood with Light

CAT. NO. RCFL12H4BTWE



A brand of **legrand**


FEATURES

- Heavy-duty sealed bearings
- Steel mounting bracket for extra strength
- Corrosion resistant plywood blades
- Hang-sure mounting
- Summer and Winter reversible action
- Colour selector switch
- Tough easy-to-clean powder coated finish
- Time setting function
- Indoor use only

BOX CONTENTS

- Motor assembly with integrated LED Light
- 4-blades
- Mounting bracket
- Instruction Sheet
- 2 x screws and lugs for bracket
- HPM Smart Controller
- 12 x screws for blades
- Cover plate and Screws
- Remote Control
- Glass Diffuser

Single Product (Qty 1)	
Cat. No.	Barcode
RCFL12H4BTWE	9321001497653

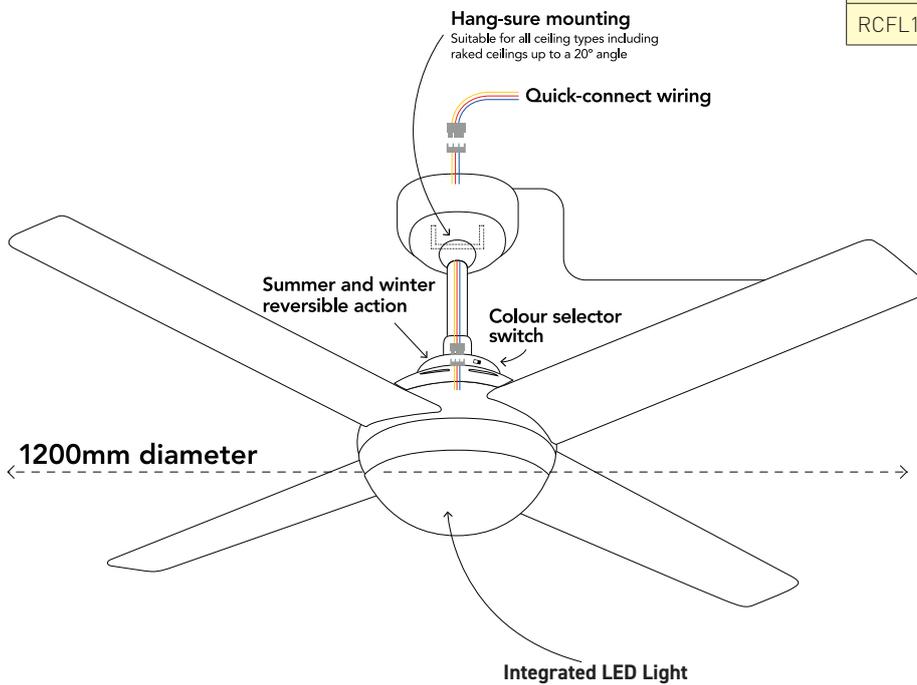

Fan Speed	RPM*	Power (Watts)
Low	100	13
Medium	160	26
High	225	50

*RPM: Rotations per Minute



Remote + Wall Mounting bracket

Legrand - Australia
1300 369 777
www.hpm.com.au
ABN 31 000 102 661

Legrand - New Zealand
0800 476 009
www.hpm.co.nz

Refer to your group buying office, Legrand Sales Representative or Legrand Sales Office for pricing.

Please note: specifications are subjected to change without prior notice.



LE13486AB

09/2022