

Datasheet

WP3 LED Weatherproof Batten IP65 – DALI Mains

CAT. NO. 659300DM, 659303DM, 659306DM



Cat. No.		659300DM	659303DM	659306DM
Description		WP3 L6 LED BATTEN DALI MAINS	WP3 L12 LED BATTEN DALI MAINS	WP3 L15 LED BATTEN DALI MAINS
Supply Voltage		230-240 V a.c. 50 Hz		
Light Source		Selectable LED (3000K/4000K/6500K)		
SDCM (MacAdam Ellipse)		3 (Warm/Natural)		
Flicker-Free		Yes		
Luminous flux (lm) (Mains mode)	Warm	3140	5140	6610
	Cool	3310	5360	6890
	Natural	3260	5350	6870
Power Consumption (W)		26	42	54
Luminaire Efficacy at 4000K (lm/W)		127	128	
Power factor		>0.8	>0.9	
Inrush Current		13.6A	35A	
IP Rating		IP65		
IK Rating		IK08		
Retaining Clips		304 Stainless Steel		
Body Construction		Polycarbonate		
Diffuser		Opal polycarbonate		
Length (mm)		664	1274	1574
Weight (kg)		1.3	2.2	2.8
Compliance		AS/NZS 60598, AS CISPR 15		
Product Marking				

Datasheet

WP3 LED Weatherproof Batten IP65 – DALI Mains


CAT. NO. **659300DM, 659303DM, 659306DM**



FEATURES

- A premium range of LED weatherproof battens.
- Available in 2 foot, 4 foot or 5 foot lengths.
- Tri-colour LED selection.
- Ideal replacement for T5 equivalents.
- LED Light Source Life:
 - 150,000hrs, L80 B50 at ambient temperature of 25°C.
 - 250,000hrs, L70 B50 at ambient temperature of 25°C.
- CRI > 90
- 5 Year Warranty.

DIMENSIONS

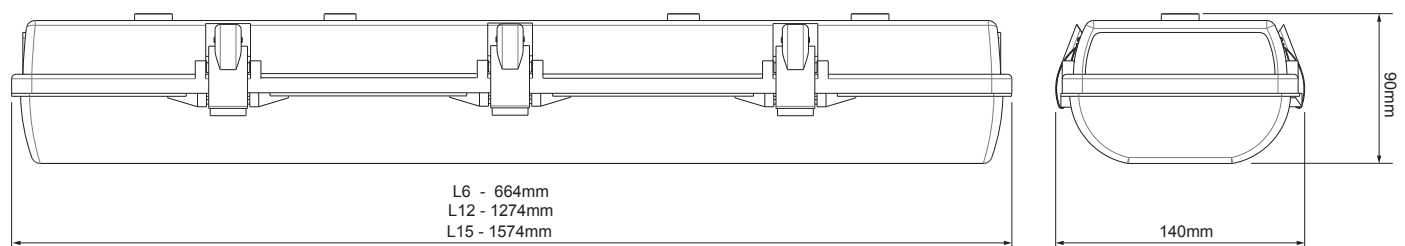

Legrand - Australia
1300 369 777
www.legrand.com.au
ABN 31 000 102 661

Legrand - New Zealand
0800 476 009
www.legrand.co.nz

Refer to your group buying office, Legrand Sales Representative or Legrand Sales Office for pricing.

Please note: specifications are subject to change without prior notice.



LE14855AB

07/2025