


## END COVER, 50 mm DUCT, WITH TWO 20 mm DIA KNOCKOUTS

Part number: TC1279-127

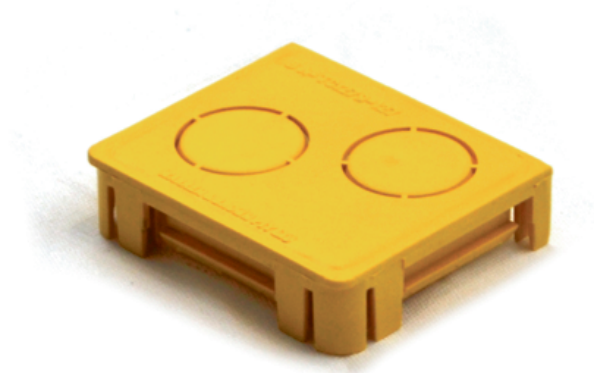

### 1. USE / APPLICATION

The duct end cover is provided with two 21 mm dia knockouts, that allow fitting of convoluted, flexible tube/s 20 mm ID/25 mm OD (Part No: TC1279-54 - 2 metres long). These convoluted tubes allow optical fibre cords to be dropped off from the duct to lower transmission equipment. The end cover is also used for sealing the open end of a standard 50 mm straight duct. It snaps simply into the duct slots and can be removed with a screwdriver should the system need extending.

### 2. BENEFITS & FEATURES

- No joiner needed
- Clips straight into 50 mm duct end
- Adapts to standard 20 mm ID/25 mm OD, convoluted tube (Part No: TC1279-54); available separately
- Tough, fire retardant material
- Purchase by the unit

### 3. TECHNICAL ATTRIBUTES

Dimensions	14 mm (W) x 47 mm (H) x 60 mm (D)
Weight	30 grams
Materials	Fire retardant plastic, Halogen free, UL94-VO rated