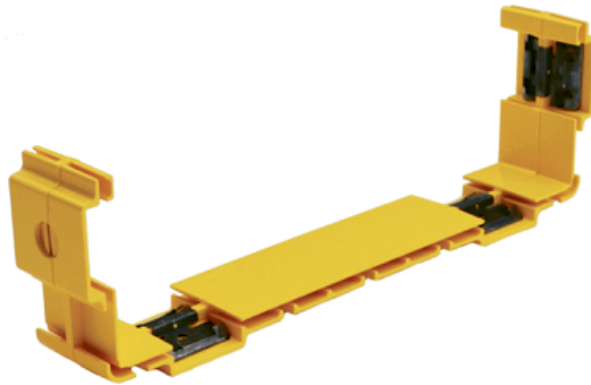


**SLOTLESS JOINER, 300 mm DUCT****Part number: TC1279-287A****1. USE / APPLICATION**

The slotless joiner is used to link standard 300 mm straight ducting with itself or any of the other 300 mm components; with which it provides a smooth & strong joint. Typical other fittings are: horizontal or vertical elbows, cross connectors, tees, etc.; which require a joiner at each interface. The slotless joiner incorporates three metal spring brackets, which securely grip with the flat face of the mating 300 mm duct components. This ensures that a positive, permanent connection is achieved. The slotless joiner is easily and simply locked or released by turning the locking slot through 90 degrees; using either a coin or wide bladed screwdriver.

**2. BENEFITS & FEATURES**

- Quickly installed on 300 mm duct components, to achieve a positive connection
- Quickly released, using either a coin or wide bladed screwdriver
- Incorporates 4 spring brackets, that make a permanent connection between 300 mm duct components
- Tough, fire retardant material
- Purchase by the unit

**3. TECHNICAL ATTRIBUTES**

Dimensions	50 mm (W) x 100 mm (H) x 324 mm (D)
Weight	138 grams
Materials	Fire retardant plastic, Halogen free, UL94-VO rated