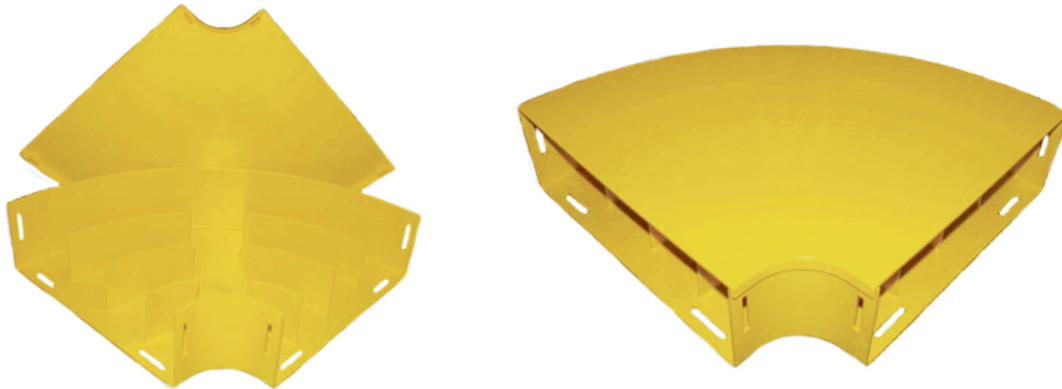


**ELBOW ASSEMBLY, 90 DEGREES,  
HORIZONTAL, 300 mm x 100 mm DUCT**

Part number: TC1279-387A

**1. USE / APPLICATION**

The 300 mm elbow is used to provide a horizontal, right angled bend (right or left hand) with standard 300 mm ducting. A single cover (Part No: TC1279-388) is supplied. A standard or slotless joiner (Part No's: TC1279-320KIT or TC1279-287A) is used at each interface, to produce a smooth and strong joint. These are available separately.

**2. BENEFITS & FEATURES**

- Provides a 90 degree bend
- Includes a cover (Part No: TC1279-388)
- Connects using either: a standard or slotless joiner (Part No's: TC1279-320KIT or TC1279-287A); which are available separately
- Tough, fire retardant material
- Purchase by the unit

**3. TECHNICAL ATTRIBUTES**

Dimensions	380 mm (W) x 115 mm (H) x 380 mm (D)
Weight	1.1 kg (Cover = 390 grams)
Materials	Fire retardant plastic, Halogen free, UL94-VO rated