


The four types of doublers

Cat. No(s) : 327 45/46/47/48

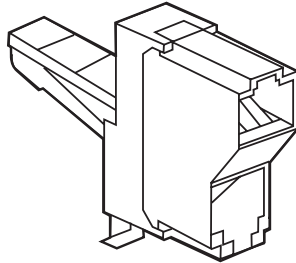

1. RANGE

Cat. Nos	Dimensions	RJ 45 outputs
327 45	30 ± 5 x 31 ± 3 x 14	1 telephone 1 Ethernet 100 base T UTP
327 46	30 ± 5 x 31 ± 3 x 14	2 telephones RJ 45
327 47	30 ± 5 x 31 ± 3 x 14	2 telephones ISDN
327 48	30 ± 5 x 31 ± 3 x 14	2 Ethernet 100 base T UTP


2. MATERIAL CHARACTERISTICS

ABS

3. TECHNICAL CHARACTERISTICS


Maximum transmission speed (tested)
100 Mbps

Double telephone RJ 45 - 327 46

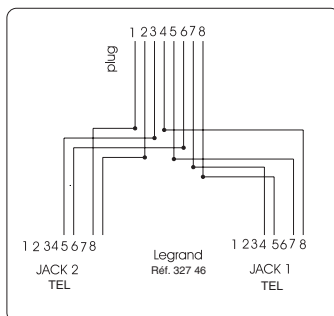


3. TECHNICAL CHARACTERISTICS (continued)


Ethernet (Jack 2) et telephone (Jack 1) - 327 45

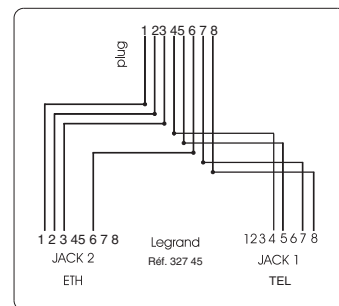

Double Ethernet - 327 48

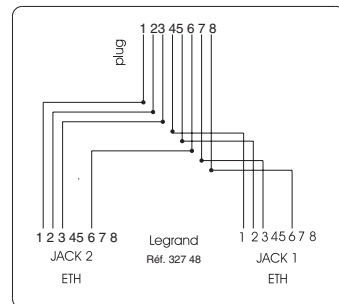

Double ISDN - 327 47

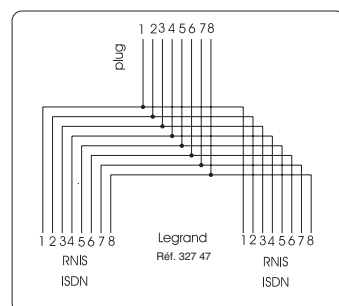

Product marking

- Connection diagram
- Date of manufacture
- Functions