 



Céliane™ Frosted and Gloss finish plates


Cat. No(s): 688 01/02/03/04/05/06/08/09/11/12/13/14/15/
18/19/21/22/23/24/25/28/29/31/32/33/34/35/38/39
688 41/42/43/44/45/48/49/51/52/53/54/58/59/61/62/63/64/65/
688/69/71/72/73/74/75/78/79
688 81/82/83/84/85/88/89/91/92/93/94/95/96/98/99



688 01/11/21/31/41/51/61/71/81/91

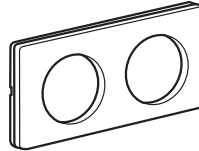

688 02/12/22/32/42/52/62/72/82/92

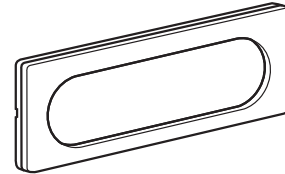

688 06/96


1. GENERAL CHARACTERISTICS

Frame plates for fitting on mechanisms, 1 to 4-gang

2. RANGE

Description	1 gang	2 gang	3 gang	4 gang	2-gang, extended	3-gang, extended	2-gang centre distance 57 mm	3-gang centre distance 57 mm
Frosted finish								
Plate Coco colour	688 91	688 92	688 93	688 94	688 95	688 96	688 98	688 99
Plate mirabelle colour	688 51	688 52	688 53	688 54	688 55		688 58	688 59
Plate Grapefruit colour	688 61	688 62	688 63	688 64	688 65		688 68	688 69
Plate Lavender colour	688 81	688 82	688 83	688 84	688 85		688 88	688 89
Plate Aniseed colour	688 71	688 72	688 73	688 74	688 75		688 78	688 79
Gloss finish								
Plate Arctic white colour	688 01	688 02	688 03	688 04	688 05	688 06	688 08	688 09
Plate Mandarin colour	688 41	688 42	688 43	688 44	688 45		688 48	688 49
Plate Magenta colour	688 11	688 12	688 13	688 14	688 15		688 18	688 19
Plate Cyan colour	688 31	688 32	688 33	688 34	688 35		688 38	688 39
Plate Bamboo colour	688 21	688 22	688 23	688 24	688 25		688 28	688 29

3. OVERALL DIMENSIONS

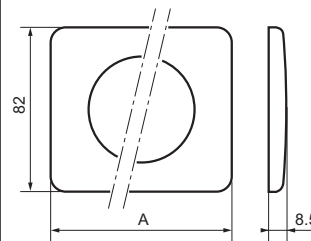

Cat. No(s)	A (mm)
688 01/11/21/31/41/51/61/71/81/91	90
688 02/12/22/32/42/52/62/72/82/92	161
688 03/13/23/33/43/53/63/73/83/93	232
688 04/14/24/34/44/54/64/74/84/94	303
688 05/15/25/35/45/55/65/75/85/95	161
688 06/96	
688 08/18/28/38/48/58/68/78/88/98	147
688 09/19/29/39/49/59/69/79/89/99	204

4. MOUNTING

The plates are clipped via notches to screw-type or claw-type supports (the notches are used to compensate for the thickness. Example: wall carpet). Easy to remove with a screwdriver using the slots on the side of the plate.

5. TECHNICAL DATA

5.1 Mechanical characteristics

Impact tests: IK 04

5.2 Material characteristics

Material: ABS + Polycarbonate
Self-extinguishing: 650°C / 30 s

5.3 Climatic characteristics

Storage temperatures: -10°C to +70°C
Operating temperatures: -5°C to +50°C

6. CLEANING

Surface cleaning with a cloth.
Do not use: acetone, tar remover, trichloroethylene

6.1 Resistance to cleaning substances

Resistance to the following products: Hexane (EN 60669-1), Methylated spirits, soapy water, diluted ammonia, diluted pure bleach 10%, glass cleaning product, pre-impregnated wipes.

6.2 Resistance to hospital-type cleaning substances

Resistance to the following products: Anios, Surfanios, Bactilyline.

Caution: A spot test should be carried out before using any other specific cleaners.

7. SPECIAL USE

The plates must not be painted.

	Cat. No(s)	Weight (g)
1-gang	688 01/11/21/31/41/51/61/71/81/91	90
2-gang	688 02/12/22/32/42/52/62/72/82/92	161
3-gang	688 03/13/23/33/43/53/63/73/83/93	232
4-gang	688 04/14/24/34/44/54/64/74/84/94	303
2-gang, extended	688 05/15/25/35/45/55/65/75/85/95	161
3-gang, extended	688 06/96	232
2-gang centre distance 57 mm	688 08/18/28/38/48/58/68/78/88/98	147
3-gang centre distance 57 mm	688 09/19/29/39/49/59/69/79/89/99	204