


# DESKTOP MULTI-OUTLETS

Number(s) : 0 535 00 to 06, 0 535 10 to 12, 0 535 15 to 21, 0 535 25 to 31, 0 535 33/34/40/41, 0 535 50 to 53, 0 535 90 to 94, 0 535 98/99, 6 535 01, 6 535 11 to 12, 6 535 15 to 16, 6 535 20 to 21, 6 535 25 to 6 535 31, 6 535 33/34/40/41, 6 535 50 to 53.

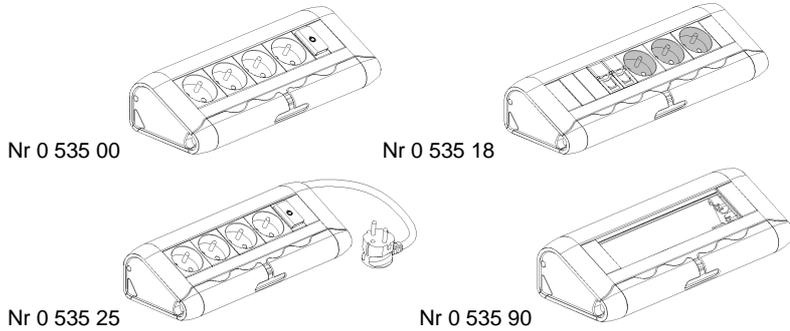

## CONTENTS

## PAGES

1 Range	1 to 2
2 Technical characteristics	3 to 4
3 Fixing	4
4 Material characteristics	4

### 1 RANGE

Desktop multi-outlets :

- an ideal solution dedicated to nomadic people and/or satisfy a esthetic needs.
- products answering all needs (pre-wired, to wire, empty or on demand)
- possibility to organise cables and plugs through the cable guide (reversible if not used)
- a specific accessory allowing to fit the product on the desk in 3 different positions.
- a reliable and secure installation with conformity to NFC 61-314
- index of protection: IK07
- 2 finishes available :
  - white wiring devices and grey end caps RAL 7035
  - stainless steel color wiring devices and end caps

#### Desktop multi-outlets prewired, white finish.

Extention (not include) to be connected to linetap

Number	Dimensions LxHxh (mm)	Functions
French std 0 535 00	277x114x75	
French std 0 535 01 German std 6 535 01	367x114x75	
French std 0 535 02	277x114x75	
French std 0 535 03	367x114x75	
French std 0 535 04	277x114x75	
French std 0 535 05	367x114x75	
French std 0 535 06	367x114x75	

### 1 RANGE (continued)

#### Desktop multi-outlets prewired, white finish (next)

Extention (not include) to be connected to linetap

Number	Dimensions LxHxh (mm)	Functions
French std 0 535 11 German std 6 535 11	367x114x75	
French std 0 535 12 German std 6 535 12	367x114x75	
French std 0 535 15 German std 6 535 15	322x114x75	
French std 0 535 16 German std 6 535 16	367x114x75	
French std 0 535 17	367x114x75	
French std 0 535 18	322x114x75	
French std 0 535 19	367x114x75	
French std 0 535 20 German std 6 535 20	367x114x75	
French std 0 535 21 German std 6 535 21	457x114x75	

# DESKTOP MULTI-OUTLETS

Number(s) : 0 535 00 to 06, 0 535 10 to 12, 0 535 15 to 21, 0 535 25 to 31, 0 535 33/34/40/41, 0 535 50 to 53, 0 535 90 to 94, 0 535 98/99, 6 535 01, 6 535 11 to 12, 6 535 15 to 16, 6 535 20 to 21, 6 535 25 to 6 535 31, 6 535 33/34/40/41, 6 535 50 to 53..

## 1 RANGE (continued)

### Desktop multi-outlets prewired, white finish (continued)

Prewired and delivered with extension cable fitted 3meters H05 VVF 3G 1.5mm<sup>2</sup> with a plug.

Number	Dimensions LxHxh (mm)	Functions
French std 0 535 25 German std 6 535 25	277x114x75	
French std 0 535 26 German std 6 535 26	367x114x75	
French std 0 535 27 German std 6 535 27	277x114x75	
French std 0 535 28 German std 6 535 28	367x114x75	
French std 0 535 29 German std 6 535 29	367x114x75	
French std 0 535 33 German std 6 535 33	367x114x75	
French std 0 535 34 German std 6 535 34	367x114x75	
French std 0 535 40 German std 6 535 40	412x114x75	
French std 0 535 41 German std 6 535 41	412x114x75	

## 1 RANGE (continued)

### Desktop multi-outlets prewired, white finish (continued)

Prewired and delivered with extension cable fitted 3meters H05 VVF 3G 1.5mm<sup>2</sup> with a plug.

Number	Dimensions LxHxh (mm)	Functions
French std 0 535 30 German std 6 535 30	322x114x75	
French std 0 535 31 German std 6 535 31	277x114x75	

0 535 30/6 535 30 equipped with :

- 2 power socket 2P+E
- 1 USB phone charge
- 1 RJ45 cat.6A FTP/UTP retractable cord (can be extended up to 0.90m)

0 535 31/6 535 31 equipped with :

- 2 power socket 2P+E
- 2 RJ45 cat.6A FTP/UTP
- 1 USB charge

### Desktop multi-outlets prewired, stainless-steel finish

Extension cable not included

Number	Dimensions LxHxh (mm)	Functions
French std 0 535 50 German std 6 535 50	367x114x75	
French std 0 535 51 German std 6 535 51	277x114x75	
French std 0 535 52 German std 6 535 52	367x114x75	
French std 0 535 53 German std 6 535 53	367x114x75	

# DESKTOP MULTI-OUTLETS

Number(s) : 0 535 00 to 06, 0 535 10 to 12, 0 535 15 to 21, 0 535 25 to 31, 0 535 33/34/40/41, 0 535 50 to 53, 0 535 90 to 94, 0 535 98/99, 6 535 01, 6 535 11 to 12, 6 535 15 to 16, 6 535 20 to 21, 6 535 25 to 6 535 31, 6 535 33/34/40/41, 6 535 50 to 53.


## 1 RANGE (continued)

Desktop multi-outlets prewired, white finish (continued)

Empty desktop multi-outlets.

Number	Dimensions LxIxH (mm)	Functions
0 535 90	277x114x75	
0 535 91	367x114x75	
0 535 92	457x114x75	
0 535 94	367x114x75	

## 2 TECHNICAL CHARACTERISTICS

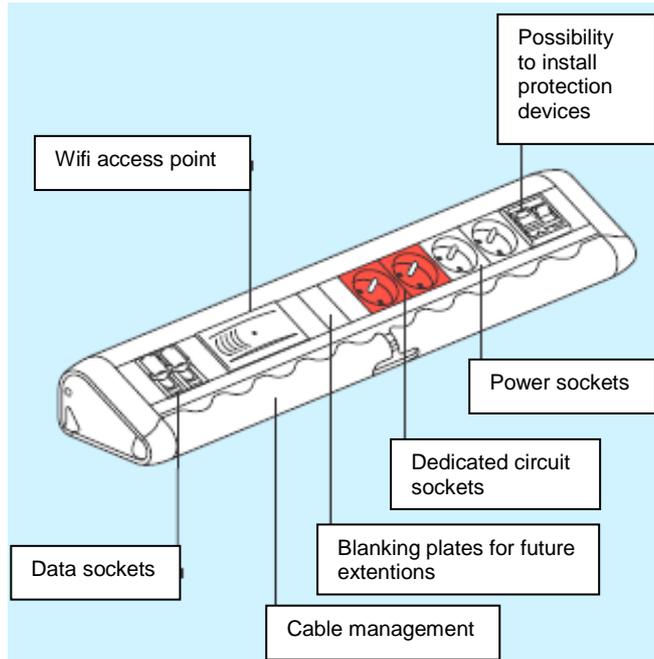

16A max (6A with filter) 3680W on 230V


## 2 TECHNICAL CHARACTERISTICS (continued)

If delivered with extension cable :

Cable type : 3 meters HO5 VVF 3G 1.5 mm<sup>2</sup>  
Plug type : 2P+T side outlet plug

Other plugs available on demand

Power on the right side (2 cables entries)

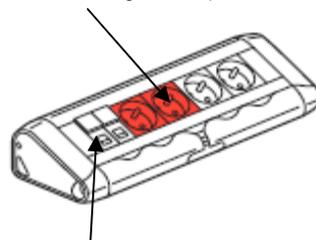


Data on the left side (6 cables entries possible)

If not delivered with extension cable :

Possibility to fit :

HO5 VVF 3G 1.5 mm<sup>2</sup> or 3G 2.5 mm<sup>2</sup> (2 entries max)  
HO7 RNF 3G 1.5 mm<sup>2</sup> or 3G 2.5 mm<sup>2</sup> (1 entry max)

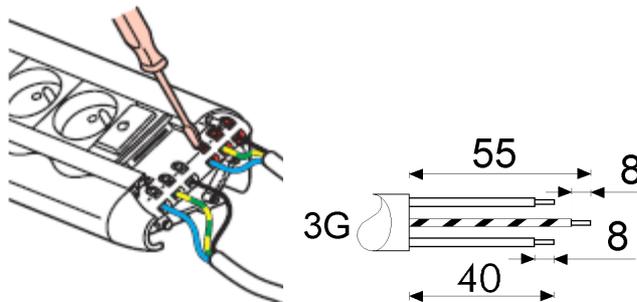


Products are delivered with cable thightener




Passing the cable through the end cap :

The end cap includes 1 cable entry.

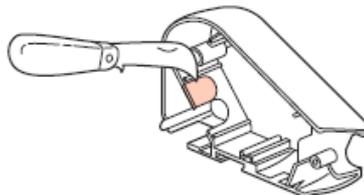

To fit a second cable, take out the part as shown above

Depending on your workstation, you can chose from where the cables go out from the outlet :

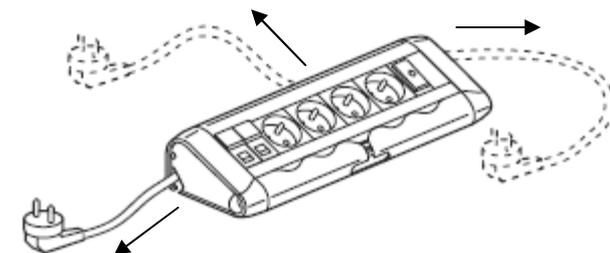


# DESKTOP MULTI-OUTLETS

Number(s) : 0 535 00 to 06, 0 535 10 to 12, 0 535 15 to 21, 0 535 25 to 31, 0 535 33/34/40/41, 0 535 50 to 53, 0 535 90 to 94, 0 535 98/99, 6 535 01, 6 535 11 to 12, 6 535 15 to 16, 6 53520 to 21, 6 535 25 to 6 535 31, 6 535 33/34/40/41, 6 535 50 to 53.


## 2 TECHNICAL CHARACTERISTICS (continued)

### Cables management :

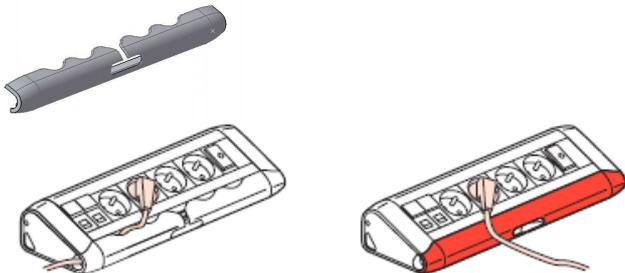

Type of screws delivered : posidrive head

### Useful information :

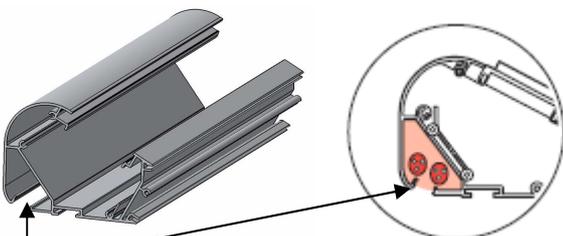

Enable you to fit 2 cables 3G 1.5 mm<sup>2</sup> or 3 data cables + 1 power cable.

Standard or on demand products body in anodized stainless steel  
End caps in ABS grey RAL 7035 or stainless steel finish  
Cable management in Polyamide RAL 7035  
Cable thightener in ABS  
Linemap in Polypropylene

## 3 FIXING

### Cable worm number 0 535 98



Very suitable solution for a safe and design protection of the cabling between desk and floor.

Pack by 1

Length : 0.75m

### Cabling capacity :

- minimum dimension of cable : 2x0,5 mm<sup>2</sup> (5mm diameter) 20 each side
- maximum dimension of cable: 5x2,5 mm<sup>2</sup> (14mm diameter) 3 each side


### Material Characteristics of Nr. 0 535 98

Ring white colour : ABS + thermoplastic polyurethane ( for the membrane)

- Fixation accessory: ABS
- Base : plastic part = EPDM
- Metal plate = FE

## 3 FIXING (continued)


### Fixing accessory Number 0 535 99.

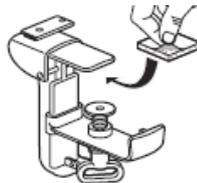


Allow fitting on a desk  
Material : Zamak (stainless steel color)

### Multi-position fixing device :

- 1- On the desk
- 2- Under the desk
- 3- Along the desk
- 4- On the desk foot

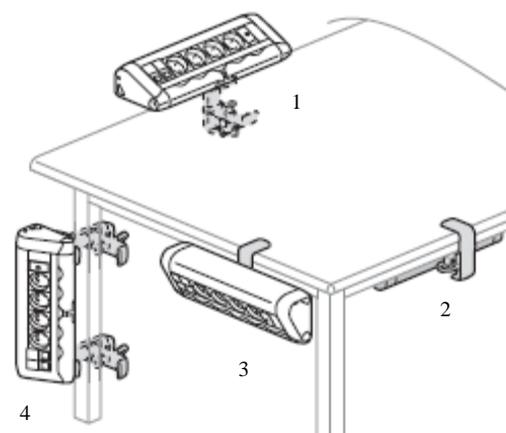

### Quantity of accessory to be used :

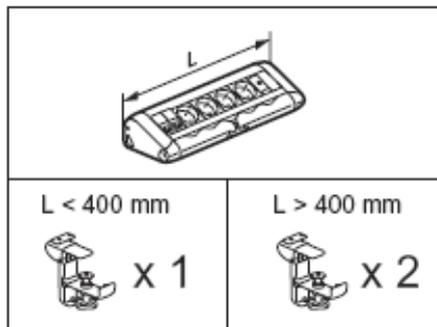

It is delivered with an adhesive desk protection accessory

