


**Mosaic™**  
**Bulkhead light for skirting lighting - antimicrobial\***

Cat. No(s): 0 785 10

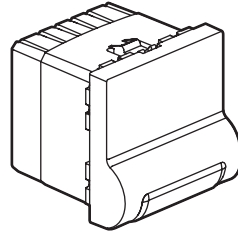


**1. USE**

Bulkhead light for skirting by LED.  
 This product is made of silver-ion based antimicrobial\* material.  
 This technology eliminates bacteria, fungi and viruses without creating any immunisation or resistance effects (physical, rather than chemical, destruction).  
 Particularly suitable for healthcare establishments (hospitals, clinics, nursing homes, laboratories, waiting rooms, etc.) and more generally for areas subject to hygiene restrictions (industrial, shared and restaurant kitchens, waste, etc.).  
 This product offers an additional way of ensuring the non-proliferation of bacteria, fungi and viruses without interfering with cleaning protocols. The mechanism can be flush-mounted or surface-mounted.  
 To be equipped with plates.  
 Fixing with clips.

**2. RANGE**

Description	White antimicrobial*
Bulkhead pilot light - 2 modules To be installed in skirting trunking or bedhead strip.	0 785 10

**3. DIMENSIONS (mm)**

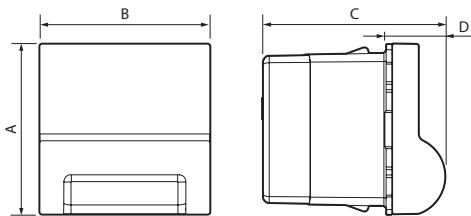


A	B	C	D
45	45	49	16

**4. CONNECTION**

Type of terminals: with screws  
 Terminal capacity: 1 x 2.5 mm<sup>2</sup> or 2 x 1.5 mm<sup>2</sup>  
 Tripping length: 8 mm  
 Screwdriver: flat 3.5 mm - philips n° 1 - posidrive n° 1 - mixed size 0

**4. CONNECTION (continued)**

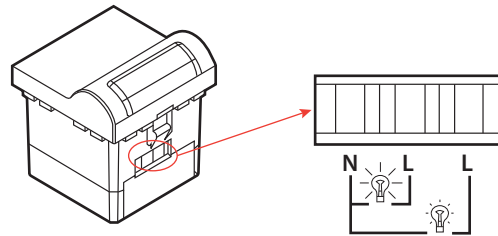

**5. TECHNICAL CHARACTERISTICS**

- **5.1 Mechanical characteristics**  
 Impact resistance: IK 04  
 Penetration against solid bodies and liquids: IP 41
  - **5.2 Material characteristics**  
 Base: Polycarbonate  
 Cover plate: ABS White RAL 9003 + antimicrobial\* surface treatment.  
 Halogen-free  
 UV resistant  
 Self-extinguishing:  
 850°C/30 s for insulating parts holding live parts in place  
 650°C/30 s for the other insulating part
  - **5.3 Electrical characteristics**  
 Voltage: 230 V  
 Frequency: 50/60 Hz
  - **5.4 Lighting levels**
- | Power: | 1 W | 0,2 W |
|--------|-----|-------|
|        |     |       |
- **5.5 Climate characteristics**  
 Storage temperature: - 10°C to + 70°C  
 Usage temperature: - 5°C to + 35°C

Mesures taken at 30 cm from ground and 10 cm from wall:  
 - In high brightness position: 1700 cd/m<sup>2</sup>  
 - In low brightness position: 350 cd/m<sup>2</sup>

## Bulkhead light for skirting lighting - antimicrobial\*

### 6. CLEANING

Clean the surface with a cloth.

Do not use acetone, tar-removing cleaning agents or trichloroethylene.

#### ■ 6.1 Resistance to cleaning products

Resistant to the following products: hexane (NF C 61-314), methylated spirit, soapy water, diluted ammonia, bleach diluted to 10%, window-cleaning products, pre-impregnated wipes.

#### ■ 6.2 Resistance to hospital grade cleaning products

Resistant to the following products: Anios, Surfanios, Bactilycine, diluted hydrogen peroxide (35%).

**Caution:** Always test before using other special cleaning products.

### 7. STANDARDS AND APPROVALS

Comply with installation and manufacturing standards.

See e-catalogue.

\*Contains silver ions that limit the development of bacteria on the surface.