


**Mosaic™**  
**Socket outlets - German standard**

**Cat. No(s): 0 772 10 - 6 771 20/26/27/29**  
**2 782 10L**

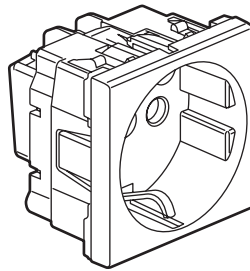

0 772 10


**1. USE**

Socket outlets without shutters for installation in flush-mounting box, surface-mounting box, floor box, column module, desktop multi-outlet extension, office module and trunking.

**2. RANGE**

Description	Colour	Cat. Nos
2 P+E socket outlet - 2 modules	White	0 772 10
	White	2 782 10L
	White	6 771 20
	Green	6 771 26
	Orange	6 771 27
2 P+E socket outlet with flap - 2 modules	White	6 771 29

**3. DIMENSIONS (mm)**

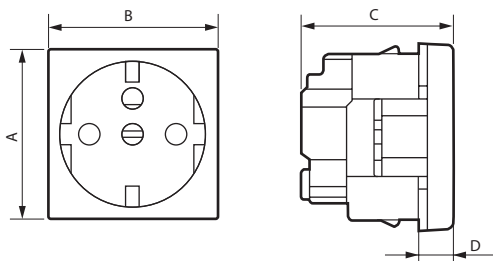

	A	B	C	D
0 772 10 - 6 771 20/26/27 2 782 10L	45	45	40	8.5
6 771 29	45	45	43	8.5

**4. CONNECTION**

Type of terminals: with screws  
 Terminals capacity: 2 x 4 mm<sup>2</sup>  
 Stripping length: 10 mm  
 Screwdriver: flat 4 mm  
 Flexible or rigid cables compatible

**5. TECHNICAL CHARACTERISTICS**

■ **5.1 Mechanical characteristics**

Protection against solid bodies and liquids: IP 20  
 Protection against impacts: IK 04

■ **5.2 Material characteristics**

Material: - Base: PC  
 - Cover plate: PC  
 - Halogen free  
 - UV resistant

Self-extinguishing:

850°C/30 s for insulating components holding live parts in place  
 650°C/30 s for other insulating components

■ **5.3 Electrical characteristics**

Voltage: 250 V~  
 Current: 16 A  
 Frequency: 50-60 Hz

■ **5.4 Climate characteristics**

Storage temperature: -10°C to +70°C  
 Operating temperature: -5°C to +50°C

**6. CLEANING**

Clean the surface with a cloth.

Do not use acetone, tar-removing cleaning agents or trichloroethylene.

Resistance to cleaning products: Hexane (EN 60669-1), methylated spirit, soapy water, diluted ammonia, pure bleach diluted to 10%, window-cleaning products, pre-impregnated wipes.

**Caution:** Always test before using other special cleaning products

**7. STANDARDS AND APPROVALS**

Compliant with installation and manufacturing standards.  
 Refer to e. catalogue.