


Céliane™ Bluetooth sound system

Cat. No(s): 0 673 22

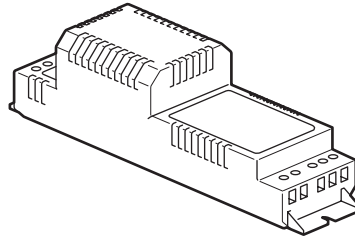


1. USE

240 V ~ / 15 Vdc direct current power supply.

2. RANGE

Description	Cat. No.
Bluetooth power supply for false-ceiling	0 673 22

3. DIMENSIONS (mm)

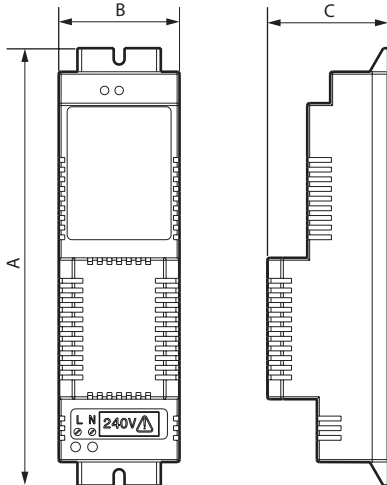

A	B	C
181	50	50

4. CONNECTION

Type of terminal : tunnel
 Terminal capacity: min. 1 mm² - max. 2.5 mm²
 Screwdriver: flat 3 mm

5. TECHNICAL CHARACTERISTICS

■ 5.1 Mechanical characteristics

Impact tests: IK 02
 Penetration against solid bodies and liquids: IP 20

■ 5.2 Material characteristics

Polyamide

Self-extinguishing:

850°C/30 s for insulating components holding live parts in place.
 650°C/30 s for other insulating components.

■ 5.3 Electrical characteristics

Power: 3.5 W
 Input voltage: 240 VAC
 Output voltage: 15 V=

■ 5.4 Climate characteristics

Usage temperature: + 5°C to + 45°C
 Storage temperature: - 10°C to + 70°C

6. CLEANING

Surface cleaning with a cloth.

7. STANDARDS AND APPROVALS

Compliant with installation and manufacturing standards.
 See e.catalogue.