



Belanko™ Push-buttons 4 A


Cat. No(s): 6 170 10/11/15/16 - 6 171 11 - 6 172 11/16
 6 173 10/11/16 - 6 174 10/11/16

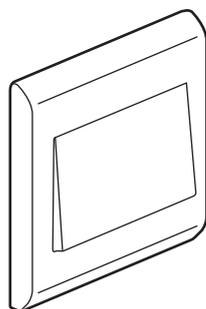

6 170 10

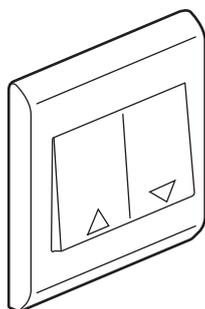

6 170 16

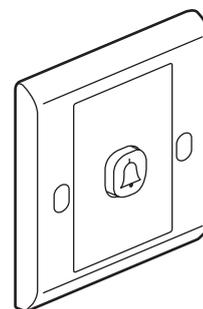

6 170 11


1. USE

Push-buttons complete delivered.
 For surface or flush-mounting box.
 Fixing with screws.

2. RANGE

	White	Ivory	Dark Grey	Brown
Bell push with small rocker	6 171 11	-	-	-
1 gang push-button with large rocker	6 170 10	-	6 173 10	6 174 10
Bell push with large rocker	6 170 11	6 172 11	6 173 11	6 174 11
2 gang push-button with large rocker	6 170 15	-	-	-
2 gang shutters push-button with large rocker	6 170 16	6 172 16	6 173 16	6 174 16

3. OVERALL DIMENSIONS (mm)

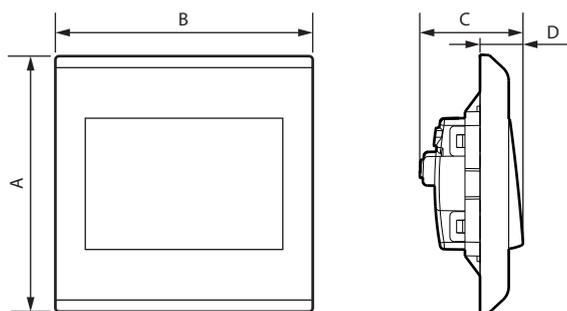

Cat. Nos	A	B	C	D
6 170 10/15 - 6 173 10 - 6 174 10	86	86	34	14.5
6 170 11 - 6 172 11 - 6 173 11 - 6 174 11	86	86	34	14.5
6 170 16 - 6 172 16 - 6 173 16 - 6 174 16	86	86	34	14.5
6 171 11	86	86	32	14.5

4. CONNECTION

Type of terminals : with screws
 Terminal capacity: 4 x 1 mm² - 4 x 1.5 mm² - 2 x 2.5 mm² - 1 x 4 mm²
 Stripping length: 8 mm
 Screwdriver: 4 mm flat blade
 Compatible with flexible or rigid cables

5. TECHNICAL CHARACTERISTICS

■ 5.1 Mechanical characteristics

Impact tests: IK 04
 Penetration by solid bodies/liquids: IP 40

■ 5.2 Material characteristics

Thermoplastic with glossy finish (White, Ivory)
 Colour: White T084: PC
 Ivory: PC
 Dark Grey: PC painted
 Brown: PC painted

Halogen free
 UV resistant

Self-extinguishing:

850° C / 30 s for insulating parts holding live parts in place.
 650° C / 30 s for other parts made of insulating materials.

■ 5.3 Electrical characteristics

Voltage: 250 V~
 Current: 4 A
 Frequency: 50/60 Hz

■ 5.4 Climatic characteristics

Storage temperature: - 10° C to + 70° C
 Use temperature: - 5° C to + 35° C

6. CLEANING

Clean the surface with a cloth.
 Do not use acetone, tar-removing cleaning agents or trichloroethylene.

Resistance to the following cleaning substances:
 Hexane (EN 60669-1), Methylated spirit, Soapy water, Diluted ammonia, Diluted pure bleach 10%, Glass cleaning product.

Caution: An initial test is required for the use of other special maintenance products.

7. STANDARDS AND APPROVALS

Compliance with standards of installation and manufacturing.
 See e.catalogue.