


Belanko™ 16 A German standard socket

Cat. no(s): 6 170 55/56 - 6 173 56 - 6 174 56

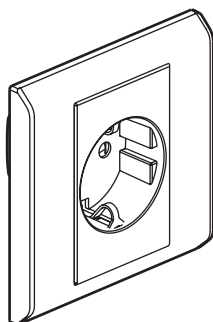


1. USE

One gang socket outlets.
 Supplied with 2 screws M3.5 for BS boxes.
 35 mm recommended depth back box.

2. RANGE

Socket outlets German standard	White	Dark Grey	Brown
1 gang socket with child protection	6 170 56	6 173 56	6 174 56
1 gang socket without child protection	6 170 55	-	-

3. DIMENSIONS (mm)

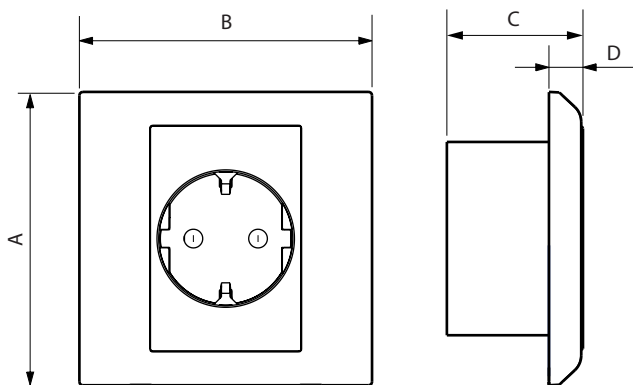

A	B	C	D
86	86	40	10

Distance of installation hole: 60.3 mm

4. CONNECTION

Type of terminals: with screws
 Terminal capacity: 2 x 2.5 mm²
 Screwdriver size: 5 mm flat blade
 Tightening torque: 0.8 Nm
 Stripping length: 12 mm

5. TECHNICAL CHARACTERISTICS

■ 5.1 Mechanical characteristics

- Impact tests: IK 04
 - Protection against solid bodies and liquids: IP 40

■ 5.2 Material characteristics

Thermoplastic with glossy finish (White)

Colour: White T084: PC

Dark Grey: PC painted

Brown: PC painted

Self-extinguishing:

+ 850°C / 30 s for insulating parts holding live parts in place.

+ 650°C / 30 s for other parts made of insulating materials.

■ 5.3 Electrical characteristics

Voltage: 250 V~

Current: 16 A

■ 5.4 Climatic characteristics

Storage temperature: - 10°C to + 70°C

Operating temperature: - 5°C to + 35°C

6. CLEANING

Surface cleaning with a soft, slightly damp cloth.
 Do not use: acetone, tar remover, trichloroethylene.

Caution: An initial test is required for the use of other special maintenance products.

7. STANDARDS AND APPROVALS

Compliance with standards of installation and manufacturing.
 See e. catalogue.