

Cover plates - 1 gang
Italian standard



HA4804...



HB4804...

CONTENTS

Page

1. Use	1
2. Range	1-2
3. Overall dimensions	3
4. Technical characteristics	4
5. Cleaning	4

1. USE

 
 

 



















 
 
Rectangular and elliptic cover plates, 1-gang, for dressing mechanisms from 2 to 6 modules.

2. RANGE

RECTANGULAR COVER PLATES - 1-gang		MODULES				
		2	3	4	6	3 + 3
ALUMINIUM						
	brushed aluminium	HA4802XC	HA4803XC	HA4804XC	HA4806XC	HA4826XC
	brushed anthracite	HA4802XS	HA4803XS	HA4804XS	HA4806XS	HA4826XS
	brushed titanium	HA4802NX	HA4803NX	HA4804NX	HA4806NX	HA4826NX
LACQUERED						
	white Limoges	HA4802BG	HA4803BG	HA4804BG	HA4806BG	HA4826BG
	red China	HA4802RC	HA4803RC	HA4804RC	HA4806RC	HA4826RC
	green Sèvres	HA4802VS	HA4803VS	HA4804VS	HA4806VS	HA4826VS
	blue Meissen	HA4802BM	HA4803BM	HA4804BM	HA4806BM	HA4826BM
ANODIZED						
	brushed chrome	HA4802CR	HA4803CR	HA4804CR	HA4806CR	HA4826CR
	brushed bronze	HA4802BR	HA4803BR	HA4804BR	HA4806BR	HA4826BR
	brushed mercury	HA4802AZ	HA4803AZ	HA4804AZ	HA4806AZ	HA4826AZ
	silver mat	HA4802SAN	HA4803SAN	HA4804SAN	HA4806SAN	HA4826SAN
WOOD						
	ashwood	HA4802LFR	HA4803LFR	HA4804LFR	HA4806LFR	HA4826LFR
	teck	HA4802LTK	HA4803LTK	HA4804LTK	HA4806LTK	HA4826LTK
	wenge	HA4802LWE	HA4803LWE	HA4804LWE	HA4806LWE	HA4826LWE
GLASS						
	black glass	HA4802VNN	HA4803VNN	HA4804VNN	HA4806VNN	HA4826VNN
	blue glass	HA4802VZS	HA4803VZS	HA4804VZS	HA4806VZS	HA4826VZS
	mirror glass	HA4802VSA	HA4803VSA	HA4804VSA	HA4806VSA	HA4826VSA
	kristal glass	HA4802VKA	HA4803VKA	HA4804VKA	HA4806VKA	HA4826VKA
STONE						
	slate	HA4802RLV	HA4803RLV	HA4804RLV	HA4806RLV	HA4826RLV
	Carrara marble	HA4802RMC	HA4803RMC	HA4804RMC	HA4806RMC	HA4826RMC

Cover plates - 1 gang
Italian standard


2. RANGE (continued)

RECTANGULAR COVER PLATES - 1-gang		MODULES				
		2	3	4	6	3 + 3
WHITE						
	AXOLUTE white	HA4802HD	HA4803HD	HA4804HD	HA4802HD	HA4826HD
	white glass	HA4802VBB	HA4803VBB	HA4804VBB	HA4806VBB	HA4826VBB
NIGHTER AND WHICE						
	nighter	HA4802VNB	HA4803VNB	HA4804VNB	HA4806VNB	HA4826VNB
	whice	HA4802VSW	HA4803VSW	HA4804VSW	HA4806VSW	HA4826VSW
ELLIPTIC COVER PLATES - 1-gang		MODULES				
		2	3	4	6	3 + 3
MÉTALLISÉ						
	AXOLUTE aluminium	HB4802XC	HB4803XC	HB4804XC	HB4806XC	HB4826XC
	AXOLUTE anthracite	HB4802XS	HB4803XS	HB4804XS	HB4806XS	HB4826XS
	solid black	HB4802NR	HB4803NR	HB4804NR	HB4806NR	HB4826NR
LIQUID						
	liquid white	HB4802DB	HB4803DB	HB4804DB	HB4806DB	HB4826DB
	liquid ivory	HB4802DA	HB4803DA	HB4804DA	HB4806DA	HB4826DA
	liquid blue	HB4802DZ	HB4803DZ	HB4804DZ	HB4806DZ	HB4826DZ
	liquid orange	HB4802DR	HB4803DR	HB4804DR	HB4806DR	HB4826DR
	liquid green	HB4802DV	HB4803DV	HB4804DV	HB4806DV	HB4826DV
GLOSSY						
	shiny gold	HB4802OR	HB4803OR	HB4804OR	HB4806OR	HB4826OR
	light titanium	HB4802TC	HB4803TC	HB4804TC	HB4806TC	HB4826TC
	silver mat	HB4802SAN	HB4803SAN	HB4804SAN	HB4806SAN	HB4826SAN
	gold mat	HB4802OS	HB4803OS	HB4804OS	HB4806OS	HB4826OS
WOOD						
	maple	HB4802LAE	HB4803LAE	HB4804LAE	HB4806LAE	HB4826LAE
	cherrywood	HB4802LCA	HB4803LCA	HB4804LCA	HB4806LCA	HB4826LCA
	walnut	HB4802LNC	HB4803LNC	HB4804LNC	HB4806LNC	HB4826LNC
STEEL						
	shiny Alessi stainless steel	HB4802AXL	HB4803AXL	HB4804AXL	HB4806AXL	HB4826AXL
	brushed Alessi stainless steel	HB4802AXS	HB4803AXS	HB4804AXS	HB4806AXS	HB4826AXS
LEATHER						
	sand leather	HB4802SLC	HB4803SLC	HB4804SLC	HB4806SLC	HB4826SLC
	coffee leather	HB4802SLS	HB4803SLS	HB4804SLS	HB4806SLS	HB4826SLS
WHITE						
	AXOLUTE white	HB4802HD	HB4803HD	HB4804HD	HB4806HD	HB4826HD
	Corian Glacier white	HB4802CGW	HB4803CGW	HB4804CGW	HB4806CGW	HB4826CGW

Cover plates - 1 gang
Italian standard


3. OVERALL DIMENSIONS (mm)

■ **Rectangular cover plates - 1-gang**

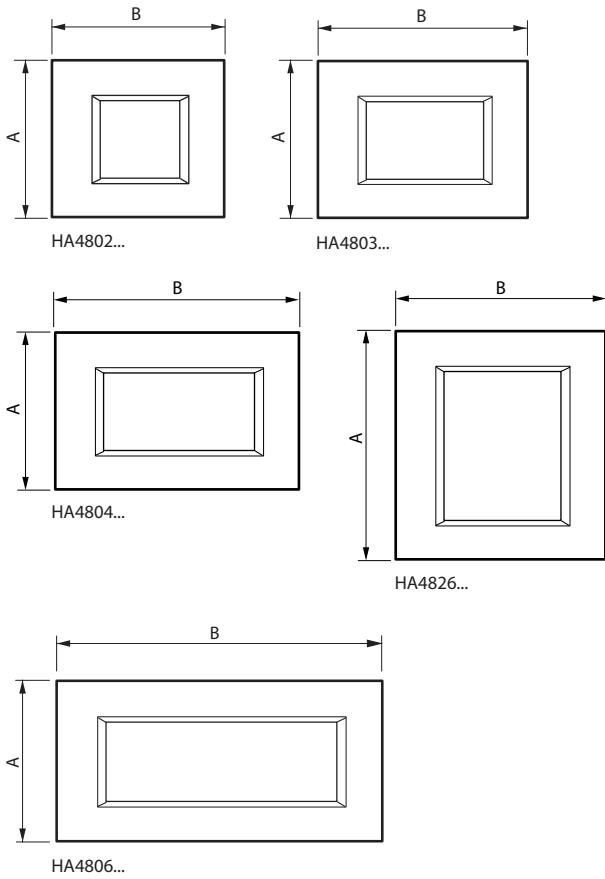

Rectangular cover plates	A	B
HA4802...	95	104
HA4803...	95	127
HA4804...	95	150
HA4806...	95	195
HA4826...	141.5	127

■ **Elliptic cover plates - 1-gang**

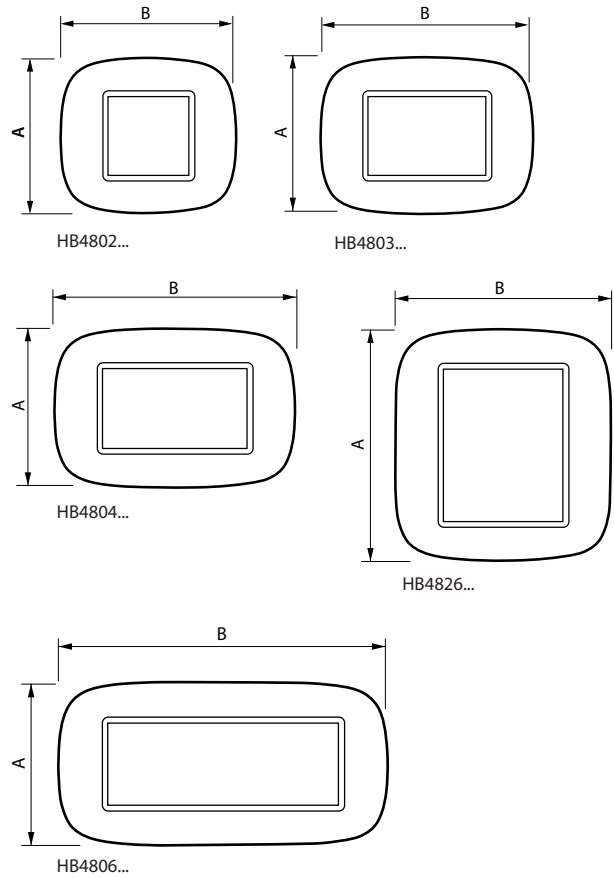

Elliptic cover plates	A	B
HB4802...	93	103
HB4803...	93	126
HB4804...	93	149
HB4806...	93	195
HB4826...	138.5	126

Cover plates - 1 gang Italian standard

4. TECHNICAL CHARACTERISTICS

■ 4.1 Mechanical characteristics

Impact test: IP 04

■ 4.2 Material characteristics

Halogen free

UV resistant

Self extinguishing:

+ 850° C / 30 s for insulating parts holding live parts in place.

+ 650° C / 30 s for other parts made of insulating materials.

Rectangular cover plates

Finish	Material	
Aluminium	Aluminium	
Lacquered	Aluminium	
Anodized	Aluminium	
Wood	Wood	
Glass	Glass	
Stone	Slate	Carrara marble
White	AXOLUTE white: Aluminium	White glass: white
Nighter and Whice	Glass	

Elliptic cover plates

Finish	Material	
Metalized	Zama	
Liquid	Plastic	
Glossy	Zama	
Wood	Wood	
Steel	Steel	
Leather	Leather	
White	AXOLUTE white: Zama	Corian glacier white: Corian

■ 4.3 Climactic characteristics

Storage temperature: - 10° C to + 70° C

Use temperature: - 5° C to + 50° C

5. CLEANING

Surface cleaning with a cloth.

Do not use: acetone, tar remover, trichloroethylene.

Caution: A preliminary test should be carried out if other specific cleaning products are to be used.