

**Quteo™**  
**Socket outlet 32 A**




**Cat. No: 7 822 22**




**1. USE**

Socket outlet with shutters and white plug.  
 Surface mounting.

**2. RANGE**

	Description	Cat. No.
	2 P+E socket with shutters	0 558 12
	Plug with lateral output cab (Cat. No 0 919 04) with cable clamp (for cable Ø 6-20 mm)	0 558 02
	Surface mounting boxe 1-gang	0 558 49

**3. OVERALL DIMENSIONS (mm)**

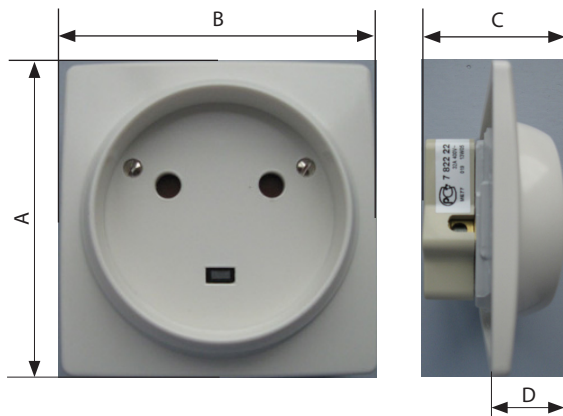

A	B	C	D
101	101	52	26

**3. OVERALL DIMENSIONS (mm) (suite)**



E	F
36	62

**4. CONNECTION**

Terminal type: with screws  
 Terminal capacity: 2 x 6 mm<sup>2</sup>  
 Recommended screwdriver size: flat blade 4 mm

**5. TECHNICAL CHARACTERISTICS**

- **5.1 Mechanical characteristics**  
 Protection against liquids: IP 20  
 Impact tests: IK 02
- **5.2 Material characteristics**  
 Mechanism housing, support frame and cover: UF  
 Framework: PS  
 Self-extinguishing:  
 + 850°C / 30 s for insulating components holding in place live parts.  
 + 650°C / 30 s for the other insulating components.
- **5.3 Electrical characteristics**  
 Voltage: 400 V~  
 Current: 32 A
- **5.4 Climatic characteristics**  
 Storage and use temperature: - 25° C to + 60° C

## 6. CLEANING

Surface cleaning with a cloth.

Do not use: acetone, tar remover, trichloroethylene.

Resistance to the following agents: Hexane (EN 60669-1), Methylated spirits, Soapy water, Diluted ammonia, Diluted pure bleached 10%, Glass cleaning substance, Pre-impregnated wipes.

**Caution:** A preliminary test should be carried out if other specific cleaning products are to be used.

## 7. STANDARDS AND APPROVALS

Compliant with installation and manufacturing standards.

See e.catalogue