



## Céliane™ Finishing plates Poudré

Cat. No(s): 0 667 01/02/03/04/05/06/08/09/11/12/13/14/15/16/18/19  
 0 667 21/22/23/24/25/26/28/29/31/32/33/34/35/36/38/39  
 0 667 41/42/43/44/45/46/48/49/51/52/53/54/61/62/63/64/71/72/73

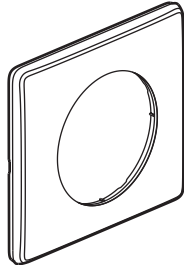

0 667 01/11/21/31/40/41/51/61/71

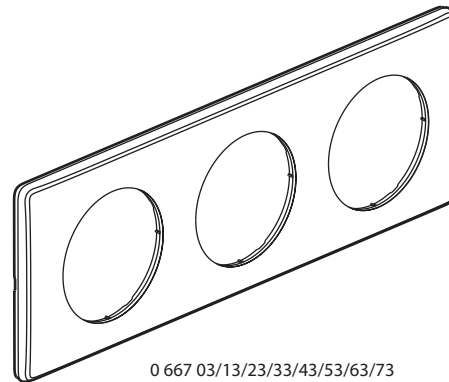

0 667 03/13/23/33/43/53/63/73

### 1. USE

Faceplates for 1-gang to 4-gang wiring accessories.  
 Horizontal or vertical mounting.

### 2. RANGE

#### Plates 1 gang

	 Craie	0 667 01
	 Argile	0 667 11
	 Grès	0 667 21
	 Schiste	0 667 31
	 Basalte	0 667 41
	 Bordeaux	0 667 51
	 Vieux Rose	0 667 61
 Bleu Vert	0 667 71	

#### Plates 2 gang - 71 mm spacing

	 Craie	0 667 02
	 Argile	0 667 12
	 Grès	0 667 22
	 Schiste	0 667 32
	 Basalte	0 667 42
	 Bordeaux	0 667 52
	 Vieux Rose	0 667 62
 Bleu Vert	0 667 72	

#### Plates 2 gang - 57 mm spacing

	 Craie	0 667 08
	 Argile	0 667 18
	 Grès	0 667 28
	 Schiste	0 667 38
	 Basalte	0 667 48

#### Extended plates 2 gang



	 Craie	0 667 05
	 Argile	0 667 15
	 Grès	0 667 25
	 Schiste	0 667 35
	 Basalte	0 667 45

### 2. GRANGE (continued)

#### Plates 3 gang - 57 mm spacing

	 Craie	0 667 09
	 Argile	0 667 19
	 Grès	0 667 29
	 Schiste	0 667 39
	 Basalte	0 667 49









#### Plates 3 gang - 71 mm spacing

	 Craie	0 667 03
	 Argile	0 667 13
	 Grès	0 667 23
	 Schiste	0 667 33
	 Basalte	0 667 43
	 Bordeaux	0 667 53
	 Vieux Rose	0 667 63
 Bleu Vert	0 667 73	

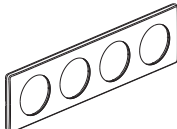
#### Extended plate 3 gang

	 Craie	0 667 06
	 Argile	0 667 16
	 Grès	0 667 26
	 Schiste	0 667 36
	 Basalte	0 667 46

#### Plates 4 gang - 71 mm spacing

	 Craie	0 667 04
	 Argile	0 667 14
	 Grès	0 667 24
	 Schiste	0 667 34
	 Basalte	0 667 44
	 Vieux Rose	0 667 54
 Bordeaux	0 667 64	

### 3. DIMENSIONS (mm)

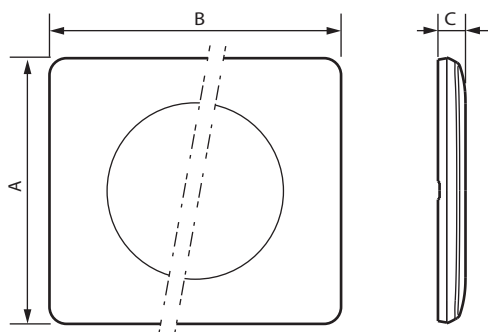

Cat. Nos	A	B	C
0 667 01/11/21/31/41/51/61/71	82	90	8,5
0 667 02/12/22/32/42/52/62/72	82	161	8,5
0 667 05/15/25/35/45	82	161	8,5
0 667 03/13/23/33/43/53/63/73	82	232	8,5
0 667 06/16/26/36/46	82	232	8,5
0 667 04/14/24/34/44/54/64	82	303	8,5
0 667 08/18/28/38/48	82	147	8,5
0 667 09/19/29/39/49	82	204	8,5

### 4. TECHNICAL CHARACTERISTICS

#### ■ 4.1 Material characteristics

PC + ABS

Halogen-free

UV-resistant

Self-extinguishing: 650°C/30 s

#### ■ 4.2 Climate characteristics

Storage temperature: - 10°C to + 70°C

Usage temperature: - 5°C to + 50°C

### 5. CLEANING

Clean the surface with a cloth.

Do not use acetone, tar-remover, trichloroethylene.

Resistance to the following products: Hexane (EN 60669-1), Methylated spirits, Soapy water, Diluted ammonia, Pure bleach to 10%, Window-cleaning products, Pre-impregnated wipes.

**Caution:** Always test before using other special cleaning products.

### 6. SPECIAL USE

The plates must not be painted.