


Valena™ Life Cable outlets

Cat. No(s): 7 534 34 - 7 535 34

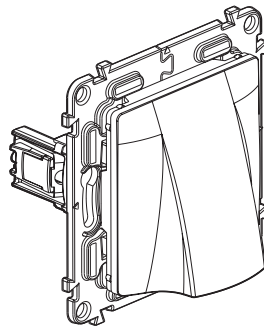

1. USE

Mechanisms supplied with:

- Support frames
- Site protection cover


To be equipped with plates.

One-gang installation, flush-mounting or surface-mounting.

2. RANGE

Description	White	Ivory
Cable outlets without terminals Equipped with cable grips Maximum diameter of the cable: 12 mm With claws	7 531 34	7 532 34


3. OVERALL DIMENSIONS (mm)

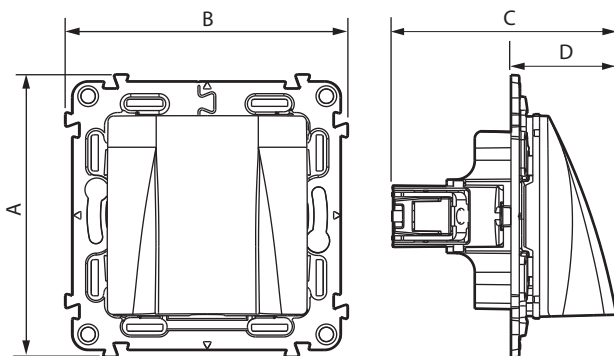

A	B	C	D
75	75	59.5	28

4. INSTALLATION

Open the support frame for the wires.

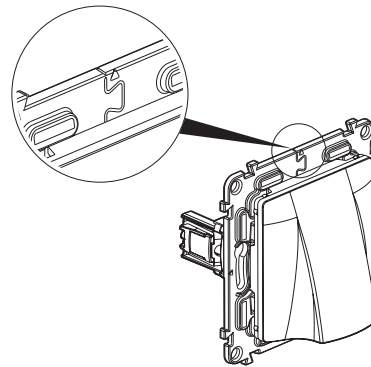

5. TECHNICAL CHARACTERISTICS

■ 5.1 Mechanical characteristics

Protection against solid bodies and liquids: IP 21
 Protection against impact: IK 04

■ 5.2 Material characteristics

Polygloss appearance

Colour: - White RAL 9003

- Ivory RAL 1013

Material: - Cover plates: ABS

- Halogen free

- UV resistant

Material of the support: - Polycarbonate grey RAL 7037

- Halogen free

Self-extinguishing:

+ 850° C / 30 s for insulating parts holding live parts in place

+ 650° C / 30 s for other parts made of insulating materials.

■ 5.3 Climatic characteristics

Storage temperature: - 10° C to + 70° C

Use temperature: - 10° C to + 40° C

6. MAINTENANCE

Surface cleaning with a cloth.

Do not use: acetone, tar remover, trichloroethylene.

Maintenance with the following products:

Hexane (EN 60669-1), Methylated spirit, Soapy water, Diluted ammonia, Bleach diluted to 10%, Window-cleaning products.

Caution: A preliminary test should be carried out if other specific cleaning products are to be used.

7. STANDARDS AND APPROVALS

Compliance with standards of installation and manufacturing.

Refer to e. catalogue.