


Valena™ Allure

Connected wireless control for roller shutters and orientable sun shades and orientable sun shades

Cat. No(s): 7 525 91 - 7 526 91 - 7 527 91
 7 528 91 - 7 529 91

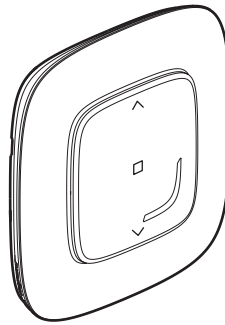

1. USE

Zone or centralised control for wired roller shutters and orientable sun shades switches.


- Fixes directly on the wall or screws onto a flush-mounting box. Multi-gang versions can be combined with other wiring accessories.
- Fits on a piece of furniture (movable).

Can control up to 20 roller shutter switches.

2. RANGE



| Description | White | Ivory | Aluminium | Black | Pearl |
|--|----------|----------|-----------|----------|----------|
| Connected wireless control for roller shutters and orientable sun shades. Supplied complete with battery. Equipped with an LED indicator (configuration) and a RESET button (hidden) used to return to factory settings. Repositionable self-adhesive fixings supplied. | 7 525 91 | 7 526 91 | 7 527 91 | 7 528 91 | 7 529 91 |

3. DIMENSIONS (mm)

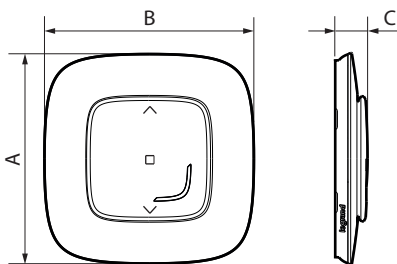

| A | B | D |
|----|----|----|
| 90 | 90 | 14 |

4. OPERATION

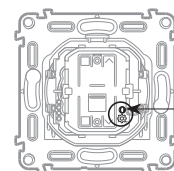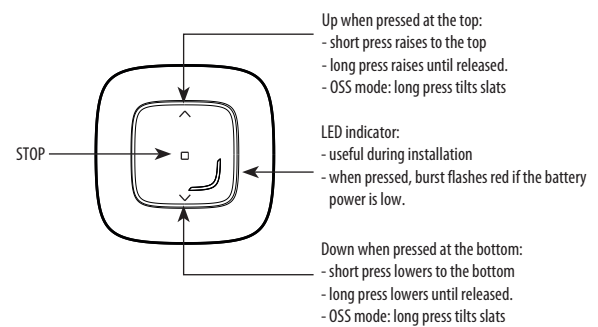

RESET button used to return to factory settings.

5. TECHNICAL CHARACTERISTICS

■ 5.1 Mechanical characteristics

Protection against impacts: IK 02
Protection against solid bodies/liquids:
- IP 20 without plate and cover plate
- IP 40 for assembled product

■ 5.2 Material characteristics

Plate: ABS
Sub-plate: PC
Rocker plate: ABS
Mechanism with grid: Fibreglass-reinforced (10%) PC
Halogen-free
UV-resistant
Self-extinguishing: 650°C/30 s

■ 5.3 Electrical characteristics

Powered by a CR2032 - 3 V lithium battery (supplied)
Battery life: 8 years for 10 activations a day

ZigBee radio technology

Frequency: 2.4 GHz to 2.4835 GHz
Power level: < 100 mW

■ 5.4 Climate characteristics

Usage temperature: + 5°C to + 45°C
Storage temperature: 0°C to + 45°C

6. CARE

Clean the surface with a cloth.
Do not use acetone, tar-removing cleaning agents or trichloroethylene.
Resistant to the following products: Hexane (EN 60669-1), methylated spirit, soapy water, diluted ammonia, bleach diluted to 10%, window-cleaning products, pre-impregnated wipes.
The plates must not be painted.

Caution: Always test before using special cleaning products.



Take care to recycle the battery appropriately

7. ACCESSORIES

0 648 71: Repositionable adhesive for wireless control (supplied)

8. STANDARDS AND APPROVALS

The undersigned, LEGRAND, declares that the radio-electric equipment type (7 525 91 - 7 526 91 - 7 527 91 - 7 528 91 - 7 529 91) complies with directive 2014/53/EU.

The full text of the EU declaration of conformity is available on the following website: www.legrandoc.com