


Niloé™ Step Cable outlets - IP44

Cat. No(s): 8 641 36

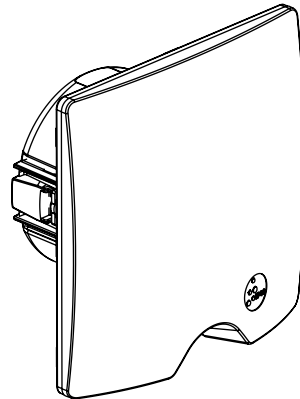


1. USE

Cable outlets.
Mechanisms supplied with protection cover.
To be equipped with plates one or several gangs.
Flush-mounting or surface-mounting.
Screw or claw fixing.

2. RANGE

Description	White
Cable outlet IP 44	8 641 36

3. DIMENSIONS (mm)

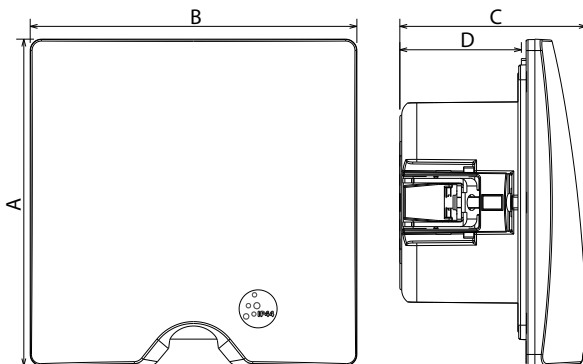

A	B	C	D
86	86	49.1	32

4. TECHNICAL CHARACTERISTICS

■ 4.1 Mechanical characteristics

Protection against solid bodies and liquids: IP 44
Protection against mechanical impact: IK 04

■ 4.2 Material characteristics

Material: - Box of the mechanism: PC
- Rocker: ABS
- Halogen free
- UV resistant
- Claws: steel
- Protection cover: SEBS

Material of the support : - PC
- Halogen free

Self-extinguishing:
+ 850° C / 30 s for insulating parts holding live parts in place.
+ 650° C / 30 s for other parts made of insulating materials.

■ 4.3 Climatic characteristics

Storage and use temperature: - 5° C to + 35° C

5. CLEANING

Surface cleaning with a cloth.
Do not use: acetone, tar remover, trichloroethylene.

Maintenance with the following products:
Hexane (EN 60669-1), Methylated spirit, Soapy water, Diluted ammonia,
Bleach diluted to 10%, Window-cleaning products.

Caution: A preliminary test should be carried out if other specific cleaning products are to be used.

6. STANDARDS AND APPROVALS

Compliant with installation and manufacturing standards.
See e.catalogue.