


Modul'up™
Hole saw

Cat. No(s): 0 885 08

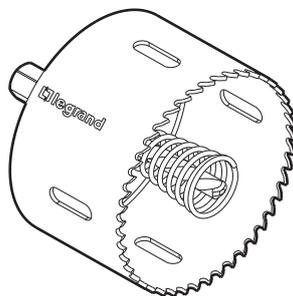


1. USE

Hole saw 80 mm diameter for mounting Modul'up box Cat. No 0 885 00.
 Use in BA10 / BA13 plasterboard type materials.
 Allows cutting VMC 80 mm ducts.
 Also suitable for installing floor outlets and chargers in furniture.

2. RANGE

Description	Reference
Hole saw with welded shaft: - HSS m ³ teeth with longer service life - M5 clamping screw - Carbide pellet pilot drill - extractor spring	0 885 08

3. DIMENSIONS (mm)

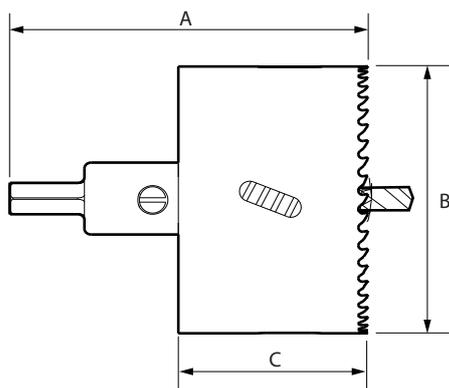

A	Ø B	C
93	80	51

Cutting diameter: 79 mm

4. TECHNICAL CHARACTERISTICS

- **4.1 Mechanical characteristics**
 The saw has an endurance > 500 holes in BA13
 It allows drilling up to 30 mm in melamine and false floor
- **4.2 Material characteristics**
 Steel
 Colour: yellow

5. CARE

Clean the surface with a cloth.
 Do not use acetone, tar-removing cleaning agents or trichloroethylene.

Caution: Always test before using special cleaning products.

6. STANDARDS AND APPROVALS

Compliant with manufacturing standards.
 See e-catalogue.