



Galion™ Connection Frame


Cat. No(s): 2 824 72/72m/73/73m/74/74m/75/75m

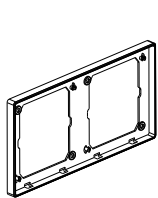


2 824 72/72m

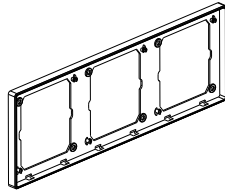

2 824 73/73m

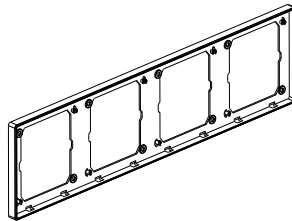

2 824 74/74m

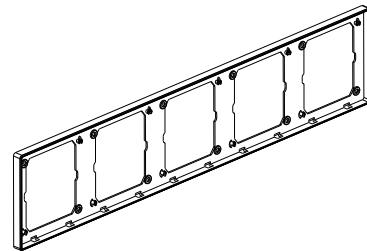

2 824 75/75m

1. USE

Multi-frame, to be equipped with 2 to 5 products.
(Supplied with M3.5 screws for BS boxes. Flush mounting or Surface mounting.)

2. RANGE


	Designation	Cat. No.
	2 Gang Frame	2 824 72/72m
	3 Gang Frame	2 824 73/73m
	4 Gang Frame	2 824 74/74m
	5 Gang Frame	2 824 75/75m

Colours


- front: white/rose golden/champagne/dark silver
- rear: white/rose golden/champagne/dark silver
- X XXX XX white
- X XXX XX-C matt black
- X XXX XX-C1 rose golden
- X XXX XX-C2 champagne
- X XXX XX-C3 dark silver

3. INSTALLATION

 
3.1 Installation diagram




4. OVERALL DIMENSIONS

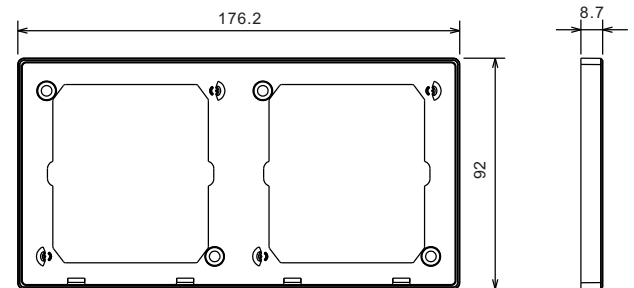


2 824 72/72m
Profile Size: 92 × 176.2 mm

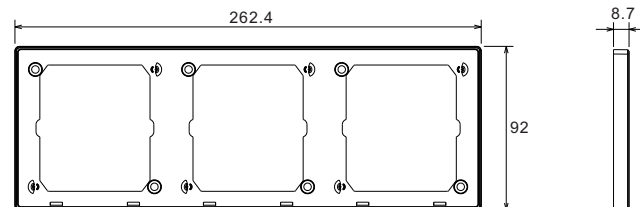

2 824 73/73m
Profile Size: 92 × 262.4 mm

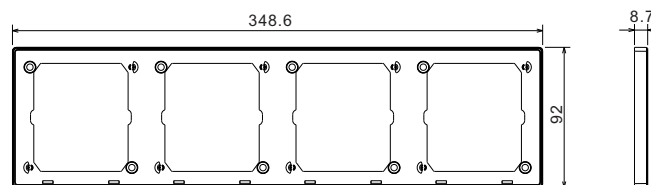

2 824 74/74m
Profile Size: 92 × 348.6 mm

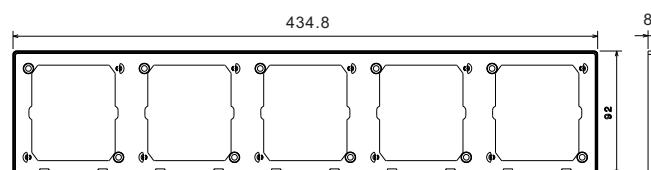

2 824 75/75m
Profile Size: 92 × 434.8 mm

5. TECHNICAL CHARACTERISTICS

5.1 Material characteristics

Frame: Polycarbonate

Self-extinguishing:

+ 650° C / 30 s for other parts made of insulating materials

5.2 Climatic characteristics

Storage temperatures: -10°C to +70°C

Operating temperatures: -5°C to +50°C

6. CLEANING

Surface cleaning with a soft, slightly damp cloth.

Do not use: acetone, tar remover, trichloroethylene

7. CONFORMITY - APPROVALS

Compliance with installation and manufacturing standards.