



Mosaic™ Cover plates


Cat. No(s): 0 788 01L/02L/03L/04L/06L/08L/10L/11L/14L/15L/16L/18L/22L/23L/25L/28L/30L/32L/36L/37L/38L/54L/56L/64L/66L
0 793 01L/02L/03L/04L/06L/08L/10L/11L/14L/15L/16L/18L/22L/23L/25L/28L/30L/32L/36L/37L/38L/54L/64L
0 790 42L/44L/46L/54L/56L/58L/62L/76L/77L - 0 994 84 - 0 788 50L/52L/62L/53L/63L - 0 791 57L

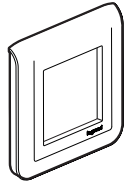


0 788 02L
0 793 02L
0 790 42L

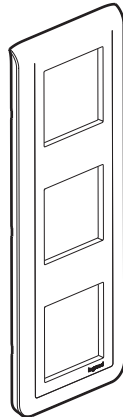

0 788 23L
0 793 23L

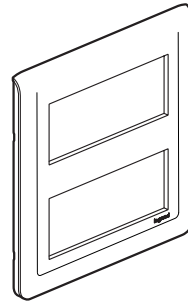

0 788 30L
0 793 30L

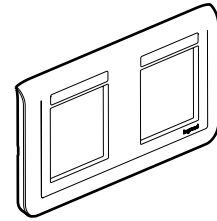

0 788 52L
Porte-étiquette

1. USE

Plates for covering mechanisms with 1 to 2 x 10 modules.
And cover plates with integrated label holder for 2 to 3 x 2 module mechanisms.


2. RANGE

| | White | Alu | Matte Black |
|-------------------------------------|-----------|-----------|-----------------------|
| 1 module narrow | 0 788 01L | 0 793 01L | - |
| 2 modules | 0 788 02L | 0 793 02L | 0 790 42L |
| 3 modules | 0 788 03L | 0 793 03L | - |
| 1-gang / 1 module | 0 788 11L | 0 793 11L | - |
| 4 modules - Horizontal | 0 788 14L | 0 793 14L | 0 790 54L 0 994 84 |
| 5 modules - Horizontal | 0 788 15L | 0 793 15L | - |
| 5 modules - Vertical | 0 788 25L | 0 793 25L | - |
| 6 modules - Horizontal | 0 788 16L | 0 793 16L | 0 790 56L |
| 8 modules - Horizontal | 0 788 18L | 0 793 18L | 0 790 58L |
| 10 modules - Horizontal | 0 788 10L | 0 793 10L | - |
| 2 x 2 modules - Horizontal | 0 788 04L | 0 793 04L | 0 790 44L |
| 2 x 2 modules - Vertical | 0 788 22L | 0 793 22L | 0 790 62L |
| 3 x 2 modules - Horizontal | 0 788 06L | 0 793 06L | 0 790 46L |
| 3 x 2 modules - Vertical | 0 788 23L | 0 793 23L | - |
| 4 x 2 modules - Horizontal | 0 788 08L | 0 793 08L | - |
| 2 x 5 modules | 0 788 30L | 0 793 30L | - |
| 2 x 6 modules | 0 788 36L | 0 793 36L | 0 790 76L |
| 2 x 8 modules | 0 788 37L | 0 793 37L | 0 790 77L |
| 2 x 10 modules | 0 788 28L | 0 793 28L | - |
| 2 x 3 x 2 modules | 0 788 32L | 0 793 32L | - |
| 2 x 2 x 2 modules | 0 788 38L | 0 793 38L | - |
| Plates 57 mm center distance | | | |
| 2 x 2 modules - Vertical | 0 788 54L | 0 793 54L | - |
| 2 x 2 modules - Horizontal | 0 788 64L | 0 793 64L | - |
| 3 x 2 modules - Vertical | 0 788 56L | - | - |
| 3 x 2 modules - Horizontal | 0 788 66L | - | - |

3. RANGE (continued)

| Plates with integrated label holder - white | |
|---|------------|
| 2 modules | 0 788 50 L |
| 2 x 2 modules horizontal | 0 788 52 L |
| 2 x 2 modules vertical | 0 788 62L |
| 3 x 2 modules horizontal | 0 788 53L |
| 3 x 2 modules vertical | 0 788 63L |

3. DIMENSIONS (mm)

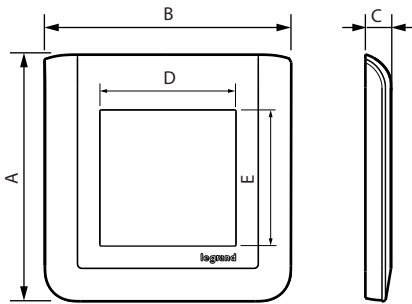

| References | A | B | C | D | E |
|--|-----|-----|-----|-------|-------|
| 0 788 01L - 0 793 01L | 82 | 40 | 8.5 | 23 | 45.5 |
| 0 788 02L - 0 793 02L - 0 790 42L 0 788 50L | 82 | 82 | 8.5 | 45.5 | 45.5 |
| 0 788 03L - 0 793 03L | 82 | 123 | 8.5 | 68 | 45.5 |
| 0 788 10L - 0 793 10L | 82 | 295 | 8.5 | 226.5 | 45.5 |
| 0 788 11L | 82 | 82 | 8.5 | 23 | 45.5 |
| 0 788 14L - 0 793 14L - 0 790 54L 0 994 84 | 82 | 153 | 8.5 | 91 | 45.5 |
| 0 788 15L - 0 793 15L | 82 | 153 | 8.5 | 113.5 | 45.5 |
| 0 788 16L - 0 793 16L - 0 790 56L | 82 | 224 | 8.5 | 136 | 45.5 |
| 0 788 18L - 0 793 18L - 0 790 58L | 82 | 224 | 8.5 | 181 | 45.5 |
| 0 788 04L - 0 793 04L - 0 790 44L 0 788 52L | 82 | 153 | 8.5 | 45.5 | 45.5 |
| 0 788 06L - 0 793 06L - 0 790 46L 0 788 53L | 82 | 224 | 8.5 | 45.5 | 45.5 |
| 0 788 08L - 0 793 08L | 82 | 295 | 8.5 | 45.5 | 45.5 |
| 0 788 22L - 0 790 22L - 0 790 62L 0 788 62L | 153 | 82 | 8.5 | 45.5 | 45.5 |
| 0 788 23L - 0 790 23L - 0 788 63L | 224 | 82 | 8.5 | 45.5 | 45.5 |
| 0 788 25L - 0 793 25L | 153 | 82 | 8.5 | 45.5 | 113.5 |
| 0 788 28L - 0 793 28L | 166 | 318 | 8.5 | 226.5 | 45.5 |
| 0 788 30L - 0 790 30L | 166 | 166 | 9 | 113.5 | 45.5 |
| 0 788 36L - 0 793 36L - 0 790 76L | 166 | 237 | 9 | 136.5 | 45.5 |
| 0 788 37L - 0 793 37L - 0 790 77L | 166 | 237 | 9 | 182 | 45.5 |
| 0 788 32L - 0 793 32L | 166 | 237 | 9 | 45.5 | 45.5 |
| 0 788 38L - 0 793 38L | 166 | 166 | 9 | 45.5 | 45.5 |
| 0 788 54L - 0 793 54L | 139 | 82 | 8.5 | 45.5 | 45.5 |
| 0 788 56L | 196 | 82 | 8.5 | 45.5 | 45.5 |
| 0 788 64L - 0 793 64L | 82 | 139 | 8.5 | 45.5 | 45.5 |
| 0 788 66L | 82 | 196 | 8.5 | 45.5 | 45.5 |

4. TECHNICAL CHARACTERISTICS

■ 4.1 Mechanical characteristics

Impact test: IK 04

■ 4.2 Material characteristics

Halogen-free

UV-resistant

Material of plates: ABS White (RAL 9003) polyglass appearance

ABS painted Aluminium varnished glittery

ABS Painted Matt Black satin finish RAL 9017

Material of subplates: PC

Self-extinguishing: 650° C/30 s

■ 4.3 Climate characteristics

Storage temperature: -10°C to +70°C

Usage temperature: -5°C to +35°C

5. CLEANING

Surface cleaning with a cloth.

Do not use: acetone, tar remover, trichloroethylene.

Caution: A preliminary test should be carried out if other specific cleaning products are to be used.


6. SPECIAL USE

Mosaic plates must not be painted.


7. ACCESSORIES

For 4, 6 and 10-module plates, use blanking plates:

| Plates | Blanking plates |
|------------|-----------------|
| 4 modules | 0 791 04 |
| 6 modules | 0 791 06 |
| 10 modules | 0 791 10 |

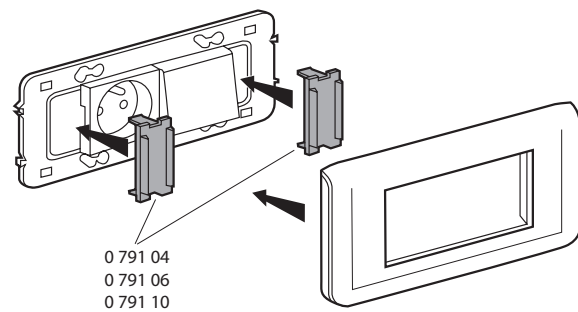

For plates with integrated label holder, accessory ref. 0 791 57L:

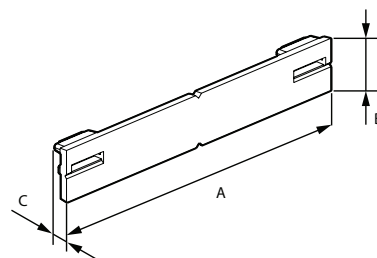

| A | B | C |
|------|---|---|
| 45,3 | 7 | 3 |