


Plexo™ Connected 2P+E socket - Waterproof

Cat. No(s): 0 697 96

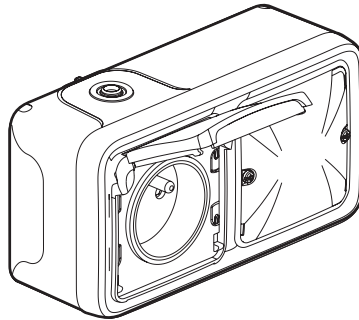


1. USE

Connected socket which can be controlled by a wireless lighting control and/or remotely via a smartphone and/or via voice assistant.
 Can be used to measure instantaneous and total consumption of the connected device, which can be viewed on the Home + Control app.
 IP55 weather proofness allows this product in rooms that are humid or dusty (cellar, garage...).
 Built-in protection against electrical overloads, for increased safety.
 Fixes directly on the wall.

2. RANGE


Description	Grey
IP55 connected 2P+E socket outlet. With activity and identification LED indicator and RESET button (hidden) used to return to factory settings. Supplied complete with surface-mounted housing.	0 697 96

3. DIMENSIONS (mm)

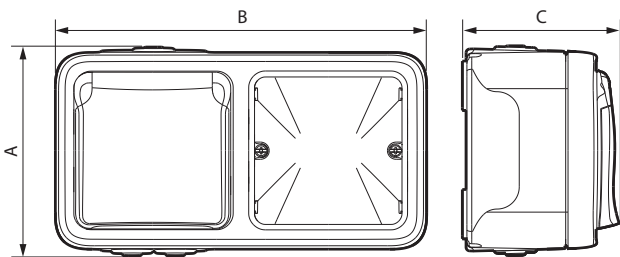

A	B	C
80	151	63


4. COMPOSITION

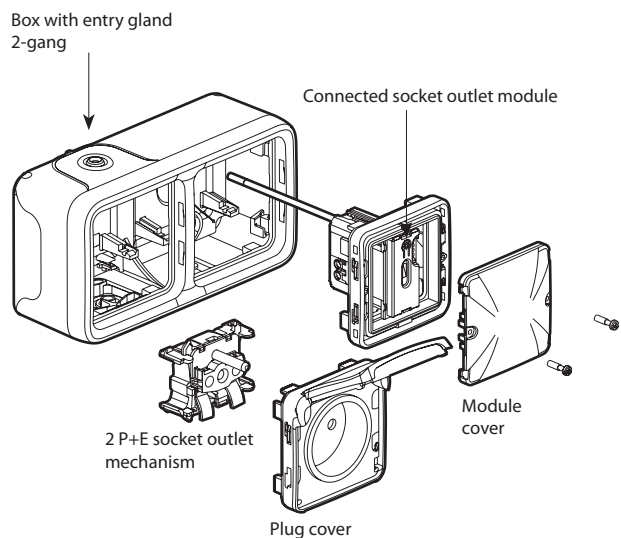

5. CONNECTION

- **2P+E socket:**
 Terminal type: automatic
 Terminal capacity: 2 x 2.5 mm²
 Stripping length: 11 mm
- **Module:**
 Terminal type: with screws
 Terminal capacity: 2 x 2.5 mm²
 Stripping length: 7 mm

6. OPERATION

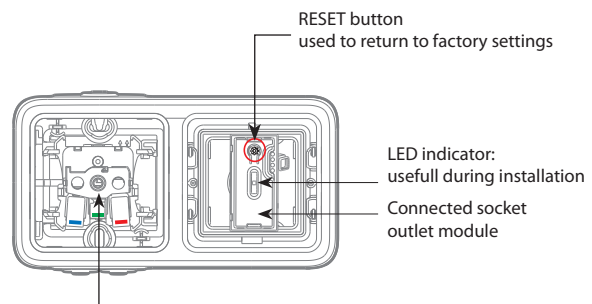

16 A connected socket outlet
 Extra built-in protection in the event of overloads of more than 16 A

7. TECHNICAL CHARACTERISTICS

■ 7.1 Mechanical characteristics

Protection against impacts: IK07

Protection against solid bodies and/or liquids: IP55

■ 7.2 Material characteristics

Module cover: ABS

Box, support : PP

Front plate, flap: ABS

Entry gland, cover plate: PP + SEBS

Halogen-free

UV-resistant

Self-extinguishing:

850°C/30 s for insulating components holding live parts in place.

650°C/30 s for other insulating components.

■ 7.3 Electrical characteristics

Voltage: 110/230 V~

Current: 16 A

Power: 3680 W max.

Standby consumption: 0.1 mA

Frequency bands: 2.4 GHz to 2.4835 GHz

Power level: < 100 mW

Range: 200 m of unobstructed space

10 m recommended between products indoors

■ 7.4 Climate characteristics

Storage temperature: 0°C to + 45°C

Usage temperature: 5°C to + 45°C

8. CLEANING

Surface cleaning with a cloth.

Do not use: acetone, tar remover, trichloroethylene.

Resistance to the cleaning products: Hexane (EN 60669-1), methylated spirits, soapy water, diluted ammonia, pure bleach diluted to 10%, window-cleaning products, pre-impregnated wipes.

Caution: Always test before using special cleaning products.

This product must not be painted.

9. STANDARDS AND APPROVALS

Compliant with installation and manufacturing standards.

See e-catalogue.

The undersigned, LEGRAND, declares that the radio-electric equipment type (0 697 96) complies with directive 2014/53/EU.

The full text of the EU declaration of conformity is available on the following website: www.legrandoc.com