



Mallia™ Senses BS 15A Switched Socket

Cat. No(s): 2 811 28/29 MW - 2 811 28/29 MG - 2 811 28/29 MB
2 811 28/29 DS - 2 811 28/29 CH - 2 811 28/29 DB
2 811 28/29 BA - 2 811 28/29 BB - 2 811 28/29 BC

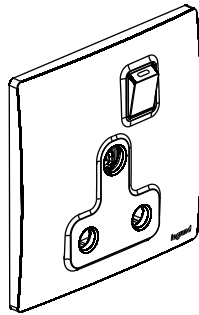

2 811 28 XX

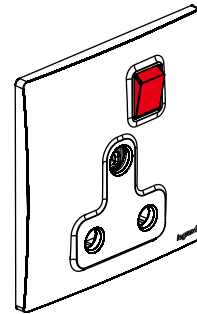

2 811 29 XX

1. USE

15A socket outlets designed to accept BS 15A plugs.
(Supplied with M3.5 screws for Flush mounting or surface mounting BS boxes.)

2. RANGE


Designation	Cat. No.
1G BS 15A SWITCHED SOCKET	2 811 28 XX
1G BS 15A SWITCHED SOCKET +LED	2 811 29 XX

Colours

-Front: MW/MG/MB/DS/CH/DB/BA/BB/BC
-Rear: grey

2 811 XX MW	Matt White
2 811 XX MG	Matt Grey
2 811 XX MB	Matt Black
2 811 XX DS	Dark Silver
2 811 XX CH	Champagne
2 811 XX DB	Dark Bronze
2 811 XX BA	Brushed Aluminium
2 811 XX BB	Brushed Black
2 811 XX BC	Brushed Champagne

3. DIMENSIONS (mm)

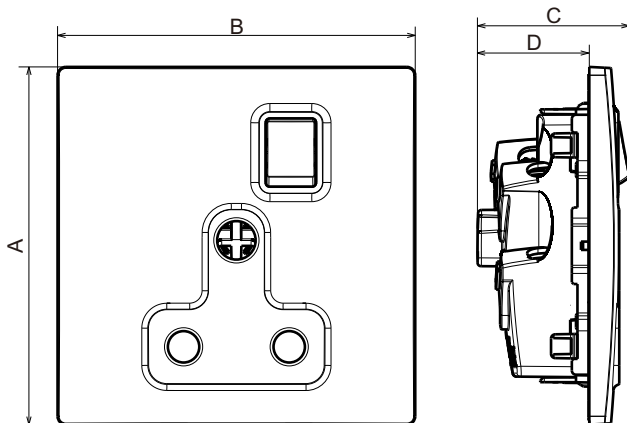

References	A	B	C	D
2 811 28 XX	86	86	36.5	26.9
2 811 28 XX	86	86	36.5	26.9

4. CONNECTION

Types of terminals: with screws

Terminal capacity: $3 \times 2.5 \text{ mm}^2$
 $2 \times 4 \text{ mm}^2$
 $1 \times 6 \text{ mm}^2$

Recommended stripping length: 12 mm

Recommended screwdriver size: <4 mm flat blade

5. TECHNICAL CHARACTERISTICS

5.1 Material characteristics

Plate/Rocker: PC

Frame: Steel

Base: PP

Self-extinguishing:

+ 850° C / 30 s for insulating parts holding live parts in place
+ 650° C / 30 s for other parts made of insulating materials

5.2 Electrical characteristics

Voltage: 250V~

Current: 15A

5.3 Climatic characteristics

Storage temperatures: -10°C to +70°C

Operating temperatures: -5°C to +50°C

5.4 Mechanical characteristics

Impact test: IK04

Protection against solids & liquids: IP20

6. CLEANING

Surface cleaning with a soft, slightly damp cloth.

Do not use: acetone, tar remover, trichloroethylene

7. CONFORMITY - APPROVALS

Conform to BS 546.