



Mallia™ Senses Loudspeaker socket

Cat. No(s): 2 810 31/32 MW - 2 810 31/32 MG - 2 810 31/32 MB
2 810 31/32 DS - 2 810 31/32 CH - 2 810 31/32 DB
2 810 31/32 BA - 2 810 31/32 BB - 2 810 31/32 BC

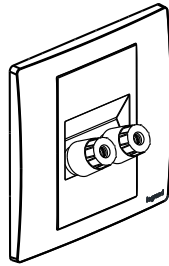

2 810 31 XX

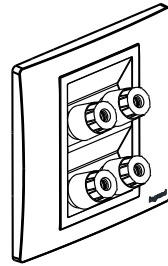

2 810 32 XX

1. USE

The switch is suitable for calling and reminding functions in family, residential area, hotel, hospital and public area.
(Supplied with M3.5 screws for Flush mounting or surface mounting BS boxes.)

2. RANGE

Designation	Cat. No.
1G LOUDSPEAKER SOCKET	2 810 31 XX
2G LOUDSPEAKER SOCKET	2 810 32 XX


Colours

-Front: MW/MG/MB/DS/CH/DB/BA/BB/BC

-Rear: Grey

2 81X XX MW	Matt White
2 81X XX MG	Matt Grey
2 81X XX MB	Matt Black
2 81X XX DS	Dark Silver
2 81X XX CH	Champagne
2 81X XX DB	Dark Bronze
2 81X XX BA	Brushed Aluminium
2 81X XX BB	Brushed Black
2 81X XX BC	Brushed Champagne

3. DIMENSIONS (mm)

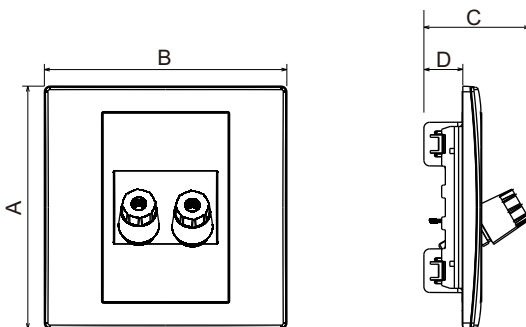

References	A	B	C	D
2 810 31 XX	86	86	37.5	13.8
2 810 32 XX	86	86	37.5	13.8

4. TECHNICAL CHARACTERISTICS

4.1 Material characteristics

Plate: PC
Frame: Steel
Self-extinguishing:
+ 650° C / 30 s

4.2 Electrical characteristics

Insulation resistance: $\geq 100M\Omega$
Contact resistance: $\leq 0.02\Omega$

4.3 Climatic characteristics

Storage temperatures: -10°C to +70°C
Operating temperatures: -5°C to +50°C

4.4 Mechanical characteristics

Impact test: IK04
Protection against solids & liquids: IP20

5. CLEANING

Surface cleaning with a soft, slightly damp cloth.
Do not use: acetone, tar remover, trichloroethylene

6. CONFORMITY - APPROVALS

Compliance with standards of installation and manufacturing.
See e.catalogue.