


Mallia™ Senses HDMI Socket + USB A

Cat. No(s): 2 810 21 MW - 2 810 21 MG - 2 810 21 MB - 2 810 21 DS - 2 810 21 CH
2 810 21 DB - 2 810 21 BA - 2 810 21 BB - 2 810 21 BC

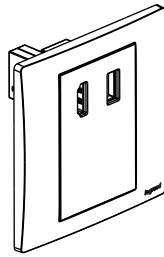

2 810 21 XX

1. USE

Used to bring connections closer to the users and to transmit high-definition digital audio video streams between a source (Blu-Ray player, computer) and a compatible receiver (e.g. TV, videoprojector) and with connecting USB devices (interactive white board, scanner/printer, external hard disk).
(Supplied with M3.5 screws for Flush mounting or surface mounting BS boxes.)

2. RANGE

Designation	Cat. No.
HDMI SOCKET + USB A	2 810 21 XX


Colours

-Front: MW/MG/MB/DS/CH/DB/BA/BB

-Rear: Black

2 810 21 MW	Matt White
2 810 21 MG	Matt Grey
2 810 21 MB	Matt Black
2 810 21 DS	Dark Silver
2 810 21 CH	Champagne
2 810 21 DB	Dark Bronze
2 810 21 BA	Brushed Aluminium
2 810 21 BB	Brushed Black
2 810 21 BC	Brushed Champagne

3. DIMENSIONS (mm)

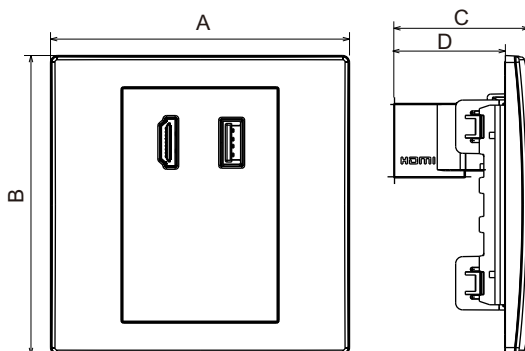

References	A	B	C	D
2 812 04 XX	86	86	38.8	32.1

Minimum depth of the box ≥ 40 mm

5. TECHNICAL CHARACTERISTICS

5.1 Material characteristics

Front: PC
Frame: Steel
Base: PC
Self-extinguishing:
+ 650° C / 30 s

5.2 Climatic characteristics

Storage temperatures: -10°C to +70°C
Operating temperatures: -5°C to +50°C

5.3 Mechanical characteristics

Impact test: IK04
Protection against solids & liquids: IP20

6. CLEANING

Surface cleaning with a soft, slightly damp cloth.
Do not use: acetone, tar remover, trichloroethylene

7. CONFORMITY - APPROVALS

Comply with installation and manufacturing standards.
Refer to e-catalogue.