



Mallia™ Senses Euro-US socket


Cat. No(s): 2 811 03/04/24 MW - 2 811 03/04/24 MG - 2 811 03/04/24 MB
2 811 03/04/24 DS - 2 811 03/04/24 CH - 2 811 03/04/24 DB
2 811 03/04/24 BA - 2 811 03/04/24 BB - 2 811 03/04/24 BC

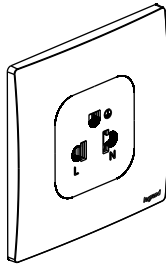

2 811 03 XX

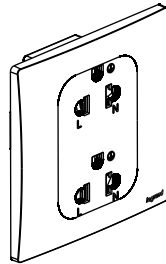

2 811 04 XX

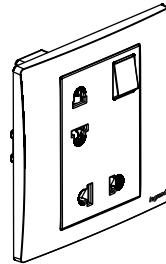

2 811 24 XX

1. USE

Euro-US socket:
(Supplied with M3.5 screws for Flush mounting or surface mounting BS boxes.)

2. RANGE

Designation	Cat. No.
1G EURO-US 16A SINGLE 2 POLES + EARTH SOCKET	2 811 03 XX
1G EURO-US 16A DUPLEX 2 POLES + EARTH SOCKET	2 811 04 XX
1G EURO-US 16A DUPLEX 2 POLES SWITCHED SOCKET	2 811 24 XX


Colours

-Front: MW/MG/MB/DS/CH/DB/BA/BB/BC

-Rear: Grey

2 81X XX MW	Matt White
2 81X XX MG	Matt Grey
2 81X XX MB	Matt Black
2 81X XX DS	Dark Silver
2 81X XX CH	Champagne
2 81X XX DB	Dark Bronze
2 81X XX BA	Brushed Aluminium
2 81X XX BB	Brushed Black
2 81X XX BC	Brushed Champagne

3. DIMENSIONS (mm)

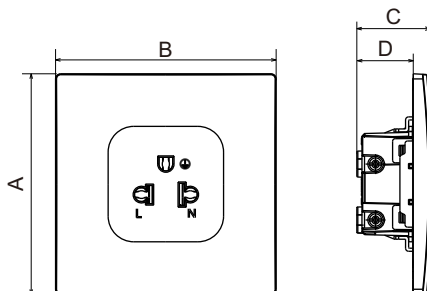

References	A	B	C	D
2 811 03 XX	86	86	28.6	22
2 811 04 XX	86	86	36.6	30
2 811 24 XX	86	86	34.6	25.3

4. CONNECTION

Types of terminals: with screws
Terminal capacity: 2 X 2.5 mm²
2 X 4 mm²
1 X 6 mm²

Recommended stripping length: 12 mm
Recommended screwdriver size: <4 mm flat blade

5. TECHNICAL CHARACTERISTICS

5.1 Material characteristics

Plate: PC
Frame: Steel
Base: PC
Self-extinguishing:
+ 850° C / 30 s for insulating parts holding live parts in place
+ 650° C / 30 s for other parts made of insulating materials

5.2 Electrical characteristics

Frequency: 50/60 Hz
Voltage: 250V~
Current: 16A

5.3 Climatic characteristics

Storage temperatures: -10°C to +70°C
Operating temperatures: -5°C to +50°C

5.4 Mechanical characteristics

Impact test: IK04
Protection against solids & liquids: IP20

6. CLEANING

Surface cleaning with a soft, slightly damp cloth.
Do not use: acetone, tar remover, trichloroethylene

7. CONFORMITY - APPROVALS

Compliance with standards of installation and manufacturing.
See e.catalogue.