


## Mallia™ Senses 45A cooker control unit

Cat. No(s): 2 810 75 MW - 2 810 75 MG - 2 810 75 MB - 2 810 75 DS - 2 810 75 CH  
2 810 75 DB - 2 810 75 BA - 2 810 75 BB - 2 810 75 BC

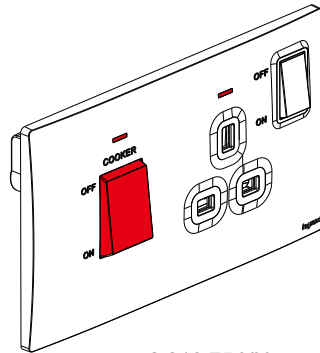

2 810 75 XX

### 1. USE

High capacity double pole switches for the control of fixed appliances eg. cooker ovens units, and 13A BS switched socket, available with LED "power on" indicator.  
(Supplied with M3.5 screws for Flush mounting or surface mounting BS boxes.)

### 2. RANGE


Designation	Cat. No.
45A COOKER CONTROL UNIT	2 810 75 XX

### Colours

-Front: MW/MG/MB/DS/CH/DB/BA/BB  
-Rear: Black

2 81X XX MW	Matt White
2 81X XX MG	Matt Grey
2 81X XX MB	Matt Black
2 81X XX DS	Dark Silver
2 81X XX CH	Champagne
2 81X XX DB	Dark Bronze
2 81X XX BA	Brushed Aluminium
2 81X XX BB	Brushed Black
2 81X XX BC	Brushed Champagne

### 3. DIMENSIONS (mm)

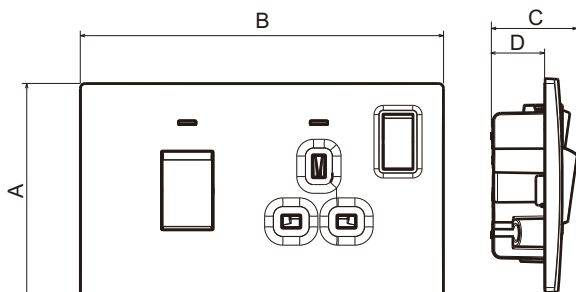

References	A	B	C	D
2 810 75 XX	86	146	34.5	21.4

### 4. CONNECTION

Types of terminals: with screws  
Terminal capacity: 2 × 6 mm<sup>2</sup>  
1 × 10 mm<sup>2</sup>  
Recommended stripping length: 24 mm  
Recommended screwdriver size: <4 mm flat blade

### 5. TECHNICAL CHARACTERISTICS

#### 5.1 Material characteristics

Rocker: PC  
Frame: Steel  
Base: PC  
Self-extinguishing:  
+ 850° C / 30 s for insulating parts holding live parts in place  
+ 650° C / 30 s for other parts made of insulating materials

#### 5.2 Electrical characteristics

Voltage: 250V~  
Current: 45A/13A

#### 5.3 Climatic characteristics

Storage temperatures: -10°C to +70°C  
Operating temperatures: -5°C to +50°C

#### 5.4 Mechanical characteristics

Impact test: IK04  
Protection against solids & liquids: IP20

### 6. CLEANING

Surface cleaning with a soft, slightly damp cloth.  
Do not use: acetone, tar remover, trichloroethylene

### 7. CONFORMITY - APPROVALS

Conform to BS 4177.