


6 010 21

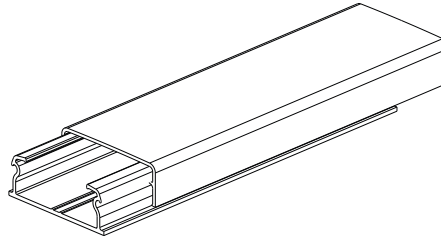

6 010 26

**1. USE**

- DLP mini-trunking offers:
- the distribution, the protection and the derivation of various cables in an electrical installation.
  - mini-trunking, finishing accessories (end cap, internal/external angle, flat angle, junction, etc...)
  - all the easy ways/advantages for the installation.
  - to comply with the norm EN 50085-2-1, safety and technical performance.
  - a flexibility with the installation and maintenance.


**2. RANGE**

■ **2.1 Mini-trunking without partition cat. nos 6 010 21/26**

Length: 2,10 m  
 Black color RAL 9017

Sections	Cat. nos	Packaging
20 x 12,5 without partition 	6 010 21	120 m
32 x 12,5 without partition 	6 010 26	80 m

Clip-on of the body and cover (unclipping with a tool for example: screwdriver).

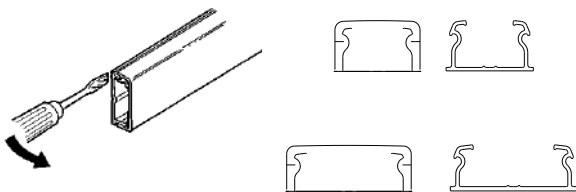

IP 40 & resistance to impact for installation and application: 2 joules.


Fixing by using:

- cartridge of adhesive neoprene for glue gun cat. no 0 309 49)
- wall plugs for immediate fixing (no screws or nail required) cat. no 0 308 98/99)
- DLP rapid wall plug (cat. no 0 308 97)
- screw, nails...

**2. RANGE (cont.)**

 ■ **2.2 Finishing accessories**

**2.2.1 End cap**




- Enables to close the end of the body:
- respect of the protection degree
  - improvement of aesthetics (covering of the cut).
- Assembly on the body by fitment and screwing.

Black color RAL 9017

Cat. nos	End cap for mini-trunking	Packaging
6 010 22	20 x 12,5	20
6 010 27	32 x 12,5	20

**2.2.2 Variable internal/external angle**

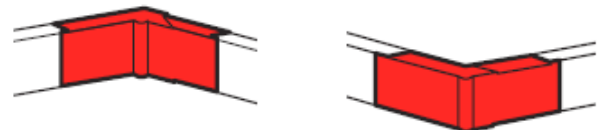

- Enables the junction of two pieces of mini-trunking of the same cross-section in an internal or external angle:
- avoids the cut of miter on the mini-trunking
  - respects of the degree protection
  - improves aesthetics (covering of the cut and not or little extra thickness)


Clip-on mounting on the body.  
 Variable internal/external angles of 60 with 120°.

Black color RAL 9017

Cat. nos	Internal/external angle for mini-trunking	Packaging
6 010 23	20 x 12,5	10
6 010 28	32 x 12,5	10

**2. RANGE (cont.)**

**2.2.3 Flat angle**

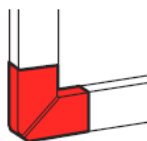

Enables the junction in flat angle of two pieces of mini-trunking of the same cross-section:

- avoids the cut of miter on the trunking
- respects of the degree protection
- preserves the distribution of the various currents
- improves aesthetics (covering of the cut)


Clip-on mounting on the body.

Flat angles are variable (85° to 95°)

Black color RAL 9017

Cat. nos	Flat angle for mini-trunking	Packaging
6 010 24	20 x 12,5	10
6 010 29	32 x 12,5	10

**2.2.4 Flat T-junction**

 

Enables the flat T-junction of two pieces of mini-trunking of the same cross-section:

- respects of the degree protection
- improves aesthetics (covering of the cut)

Clip-on mounting on the body.

Black color RAL 9017

Cat. nos	Flat T-junction for mini-trunking	Packaging
6 010 25	20 x 12,5	10
6 010 30	32 x 12,5	10

**3. GENERAL CHARACTERISTICS**

**Material characteristics:**

DLPlus mini-trunking: black color RAL 9017 PVC

- Accessories: black color RAL 9017
- ABS (flat angle, T junction, endcap)
  - PA66 (internal/external angle)

**Classification for DLPlus mini-trunking EN 50085-2-1:**

6.2 Resistance to impact for installation and application	2.0J
6.3 Minimum storage and transport temperature	- 25°C
6.3 Minimum installation and application temperature	- 5°C
6.3 Maximum application temperature	+ 60°C
6.4 Resistance to flame propagation	Non-flame propagating
6.5 Electrical continuity characteristic	Without electrical continuity characteristic
6.6 Electrical insulating characteristic	With electrical insulating characteristic
6.7 Degrees of protection provided by enclosure	IP 40
6.9 The system access cover retention	With a tool
6.101 The position when surface mounted	Wall fixed
6.102 The functions provided	Type 1
Rated voltage	500 V
Protection against mechanical shocks	IK 07

**Composition and function of DLPlus black color mini-trunking system EN 50085-2-1:**

Mini-trunking		
Body/cover	Cat. nos	Section (mm <sup>2</sup> )
20 x 12,5 without partition	6 010 21	160
32 x 12,5 without partition	6 010 26	285